

V1824D

LED Vanity

Features

Housing

Die-formed Cold-rolled Steel

Finish Option: -30 Oil Rubbed Bronze, -62 Satin Nickel, -05 Black, -06 White, -09 Silver

Optical

Shade: High Transmission Acrylic Create Excellent Light Distribution and Uniformity

LED: High Efficiency, High CRI, Binned and Mixed to Reach Uniform Light.

Electrical

High Power Factor, Low THD

Lamp


LED Module: Multiple Color Temperature (MCT), Adjustable, 3000K/3500K/4000K

Certification

ETL/cETL Listed, Damp Rated

Warranty

5 Years Warranty on Driver and LED Module

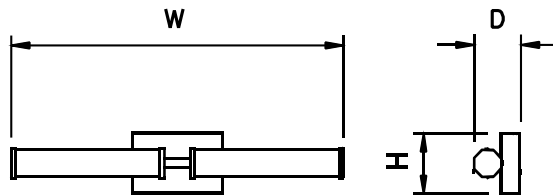

LED Type

Model	Input Voltage	Input Wattage	LED CT	CRI	Lumen (TYP)	Finish	Dimension (W X H X D)	Energy Star
V1824D-MCT-62	120V – 277V	16W	3000K/3500K/4000K	>80	1300	Satin Nickel / Acrylic	26.0" x 4.7" x 3.7"	---