

V6624D-MCT V6636D-MCT V6648D-MCT

LED Vanity

Features

Housing

Die-formed Cold-rolled Steel

Finish Option: - 30 Oil Rubbed Bronze, -62 Satin Nickel, -05 Black, -06 White, -09 Silver

Optical

Shade: High Transmission Acrylic Create Excellent Light Distribution and Uniformity

LED: High Efficiency, High CRI, Binned and Mixed to Reach Uniform Light.

Electrical

High Power Factor, Low THD

Lamp


LED Module: Multiple Color Temperature Type (MCT, Adjustable, 3000K/3500K/4000K)

Certification

ETL/cETL Listed, Damp Rated, CEC Listed (Title 24)

Warranty

5 Years Warranty on Driver and LED Module

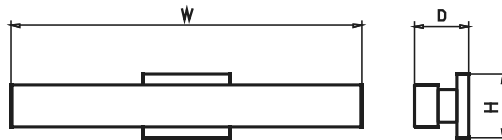

LED Type

Model	Input Voltage	Input Wattage	LED CT	CRI	Lumen (TYP)	Finish	Dimension (L X H X E)	Energy Star	CEC Listed
V6624D-MCT-62	120V – 277V	15W	3000K/3500K/4000K	>80	1550	Satin Nickel	24.0" x 4.3" x 3.7"	Yes	Yes
V6636D-MCT-62	120V – 277V	22W	3000K/3500K/4000K	>80	1900	Satin Nickel	36.0" x 4.3" x 3.7"	Yes	---
V6648D-MCT-62	120V – 277V	32W	3000K/3500K/4000K	>80	3000	Satin Nickel	48.0" x 4.3" x 3.7"	---	---