


PCSM8524C

Stream Bath Light
Polished Chrome

QUOIZEL
LIGHTING

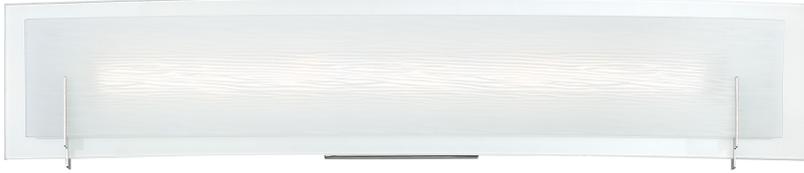

DETAILS

Material: STEEL

Glass/Shade Description: White Etched Glass
- Glass - Frosted

Shade 2 Description: Curved etched glass
with clear cente - Glass

LAMPING

Light Source: Integrated LED

ELECTRICAL

Dimmable: Yes

Dimmable To: 10.00%

Dimmer Type: CL, ELV

Voltage: 120v

Wire Length: 0.5'

INSTALLATION

ADA: Yes

Location Rating: Damp

Install Position: Horizontal

DIMENSIONS

Dimensions: 23.50" W x 5.00" H x 3.00" D

Backplate Dimensions: 4.50"H x 4.50"W

HCWO: 2.5"

Weight: 4.62 lbs

We reserve the right to revise the design of components of any product due to parts availability or change in our Listed Mark standards without assuming any obligation or liability to modify any products previously manufactured and without notice. This literature depicts a product DESIGN that is the SOLE and EXCLUSIVE PROPERTY of Quoizel Inc. Compliance with U.S. COPYRIGHT and PATENT requirements, notification is hereby presented in this form that this literature, or this product depicts, is NOT to be copied, altered or used in any manner without the express written consent of, or contrary to the best interests of Quoizel Inc. 03/31/2013