

GS

A35


LED CANOPIES



GS-CANOPY-SMB



Top view

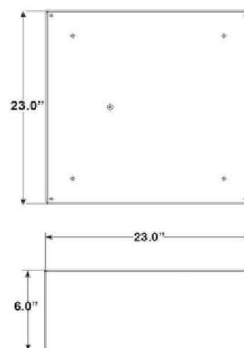

GS-CANOPY-SMB

TECHNICAL SPECIFICATIONS:


- :: New pattern design
- :: LED: SMD technology (PHILIPS LUXEON 3030 2D)
- :: Mounts to standard junction boxes
- :: Easy installation
- :: Recessed or shoebox installation available
- :: High light efficiency: 130LM/W
- :: Eliminate the relamping cycle
- :: Ultra slim at 18mm
- :: IP66, providing a reliable weather-tight seal

FEATURES:


- :: Efficiency: Up to 130LM/W
- :: Power efficiency: More than 95%
- :: CRI: >80
- :: Color temperature: 5000K
- :: Working temperature: 30°F~130°F
- :: Life span: 70,000hrs.
- :: Warranty: 5 years

APPLICATIONS:

- :: Airport, auto dealership, corporate and office, education, government, healthcare, industrial and warehouse, municipal, parking, gas station and convenience stores, recreation and public venues, restaurants and hospitality, retail and grocery.

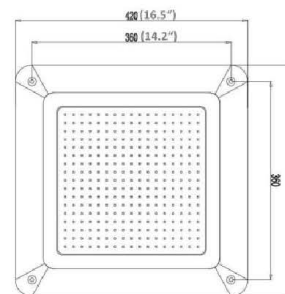

GS-CANOPY

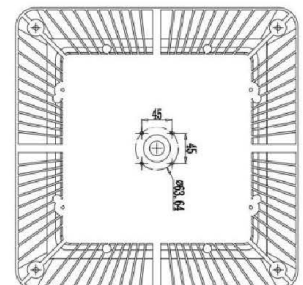

LED GAS STATION/CANOPY LIGHTS

CATALOG NO.	WATTS	LUMENS	COLOR TEMP	DIMENSIONS
GS-CANOPY-100W-50K	100W	13600LM	5000K	16" square x 8"-3/5 (H)
GS-CANOPY-120W-50K	120W	16300LM	5000K	
GS-CANOPY-150W-50K	150W	20558LM	5000K	
GS-CANOPY-SMB	Optional surface mounting shoebox - fixture not included			18" square x 5" (H)

