

A19

# LFCO-600W




### TECHNICAL SPECIFICATIONS:


- :: Housing: Die-cast aluminum housing with powder coat finish (Dark Bronze)
- :: Trunion bracket included
- :: Voltage: 120-277V
- :: 0~10V dimming
- :: optic lens - TYPE III
- :: Cord type: 6' SJTW 18/3 AWG cable
- :: Power Factor: .9~.97
- :: Operating Temp: -40°F to 104°F
- :: 150 lumens per watt
- :: CRI: 82~84
- :: 70,000 hour rated life
- :: 7-year warranty
- :: Suitable for Wet Locations, IP65

### APPLICATIONS:

- :: Ideal for general site lighting, alleys, loading docks, doorway, pathway and parking areas.
- :: Great for use with motion sensors or other instant on/off controls

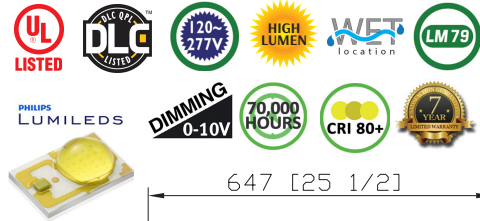

- OPTIONS**
- PHOTOCELL
- MOTION SENSOR
- BATTERY BACKUP
- FIXTURE COLOR

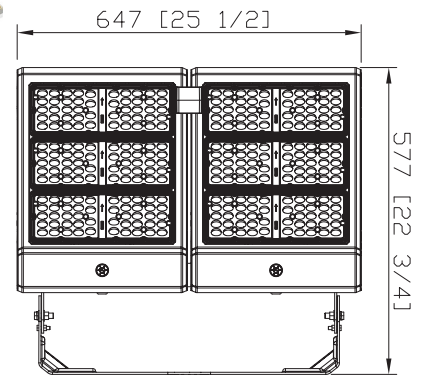

## LFCO HIGH LUMEN SERIES WITH MOUNTING OPTIONS

CATALOG NO.	WATTS	LUMENS	COLOR TEMP	REPLACEMENT RANGE	VOLTAGE	DIMENSIONS
LFCO-HL-600W-50K-TR	600W	90000LM	5000K	1000~1200 MH	120-277V	22-3/4"(H) x 25-1/2"(W) x 4-7/8"(D)

### MOUNTING OPTIONS



**LFCO-SF**  
Adjustable Slip Fitter for Pole Mount 2"–2-1/2"



**LFCO-YK**  
Adjustable Yoke



**LFCO-SA**  
Straight Arm for Shoe Box Applications  
Fits Square & Round Poles, 3" Wide