


DIMENSIONS:

9"(L) x 9"(W) x 4-1/2"(H)

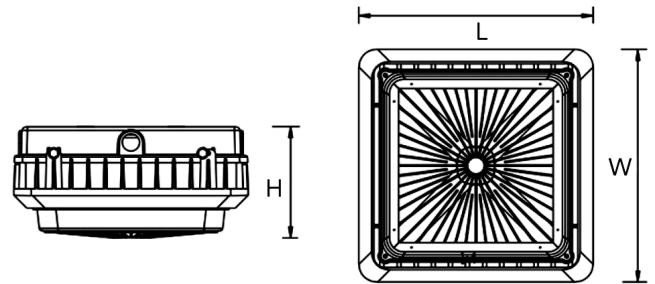

CGL-40W-50K
CGL-40W-40K

LED CANOPY/GARAGE LIGHT

Ideal for indoor parking lot, commercial buildings, schools, warehouse, retail centers, apartment, complexes,

ELECTRICAL SPECIFICATIONS:

- Voltage: 120~277VAC, 50/60 Hz
- Wattage: 40W
- Power factor: 0.90
- Efficacy: 130LM/W

HOUSING SPECIFICATIONS:

- Die-cast aluminum with prismatic polycarbonate lens
- Designed for 9 to 16-foot mounting heights
- 1/2" threaded hubs located on two sides of the housing
- Operating temperature: -4°F to 113°F
- Lifespan: 70,000 hr.
- IP Rating: IP65, Suitable for Wet Locations

CERTIFICATIONS: UL, DLC



OPTIONAL MOUNTING ARMS:

MODEL	DESCRIPTION
CGL-FL1	Side Frosted Lens for CGL-40W

LIGHTING SPECIFICATIONS:

- Dimmable: 0~10V Dimming
- Lens: prismatic polycarbonate lens
- LED: Philips Lumileds LEDs
- Total lumens: 5200LM
- Color temperature: 5000K/4000K
- Color rendering index: >80

WARRANTY: 7 years

