

LF3 SERIES Outdoor Lighting

LF3-15WW-KN
LF3-15NW-KN
LF3-15CW-KN



Selection:




Customer Name: _____

Project Name: _____

Note: _____

Type: _____

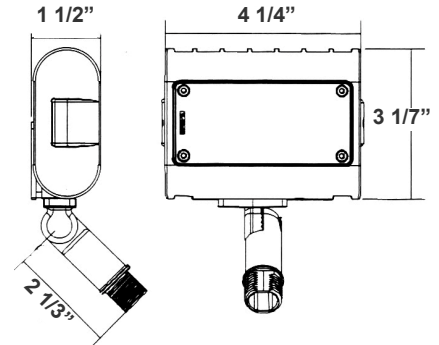

4-1/4"(W) x 3-1/7"(H) x 1-1/2"(D) x 2-1/3"(K)

Ideal for general site lighting, alleys, loading docks, doorways, pathways, parking areas. Replace existing HID flood lights/wall packs. Great for use with motion sensors or another instant on/off controls. Solid-state lighting technology for long life, low maintenance, and high efficiency.

Features

- DLC Premium & LED High-Lumen Floor lights
- LF3 Flood Light Series With 1/2" Knuckle
- 70,000 Hours Rated Life
- 7-Year Warranty
- Optic Lens Type: II

Technical Specifications

Electrical:

- Voltage: 100-277VAC 50/60Hz
- Wattage: 15W
- Output voltage: 36-60VDC
- Power factor: >0.9
- Output Current: 0.25A
- Driver Efficiency: 88%

Lighting:

- LED: Philips Lumileds Lexeon 3030 high flux LED
- Cord type: 13" #18 AWG stranded wires
- Total lumens: 1700LM
- Color temperature: 3000K/ 4000K/ 5000K
- Color rendering index: CRI ≥ 82
- Beam Angle: 120°x90°

Mechanical:

- Die-cast Aluminum Housing with Powder Coat Finish (Dark Bronze and White Finish)
- Solid State Lighting technology for long life, no Maintenance needed and High-Efficiency
- High Conductive Aluminum LED Board
- IP Rating: IP65
- Operating Temperature: -40°F to 104°F
- Suitable for Wet Locations

Applications:

- Ideal for general site lighting, alleys, loading docks, doorway, pathway and parking areas.
- Replace existing HID flood lights/ wall packs
- Great for use with motion sensors or other instant on/off controls



Other Models:

- 30W | 3600LM | LF3-30WW-KN
- 30W | 3600LM | LF3-30NW-KN
- 30W | 3600LM | LF3-30CW-KN
- 50W | 6100LM | LF3-50WW-KN
- 50W | 6100LM | LF3-50NW-KN
- 50W | 6100LM | LF3-50CW-KN




Photometrics: LF3-15W

TYPE II

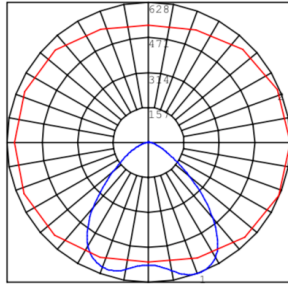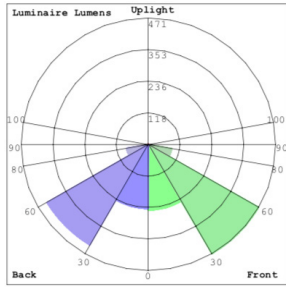

BUD Rating: B1-U1-G0

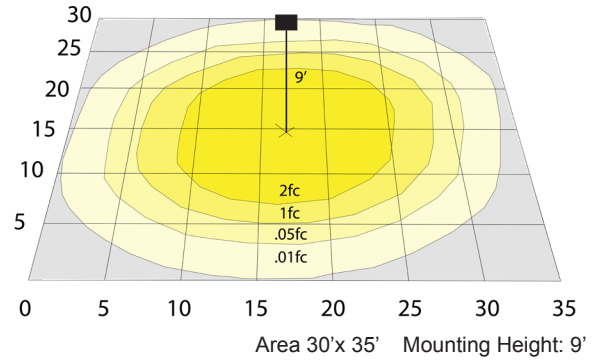

Other Views:



Front View



Side View



Back View

Performance Table: LF3-15W

MODEL NO.	Wattage	Voltage	Lumens	Color Temp.	BUG Rating	LPW
LF3-15WW	15W	120~277V	1700LM	3000K	B1-U1-G0	113
LF3-15NW	15W	120~277V	1700LM	4000K	B1-U1-G0	113
LF3-15CW	15W	120~277V	1700LM	5000K	B1-U1-G0	113

Sample Ordering

Model Wattage Color Temp.

LF3 - 15 - - KN

WW = 3000K
NW = 4000K
CW = 5000K

Accessories Options

Blank = No Option For Accessories

WRC-3-BRZ = Weatherproof cover with three(3) 1/2" hubs

LA-90-BZ = Fixture mounting 90° elbow Attachment

Example:

- 1.LF3-15WW-KN (For LF3 15W 3000K fixture 120-277V)
- 2.LF3-15WW-KN (For LF3 15W 3000K fixture 120-277V)
- WRC-3-BRZ (Weatherproof cover with three(3) 1/2" hubs)

ACCESSORIES AND MOUNTING OPTIONS



WRC-3-BRZ
Weatherproof cover with
Three
(3) 1/2" hubs



LA-90-BZ
Fixture mounting 90°
elbow Attachment



B-41



Mounts to landscape post
or any 1/2" hub



Fully adjustable 1/2"
threaded knuckle for aiming
versatility

