




Fixture is prewired with 16/3 SO cord



LF series floods are prewired with 18" cord (18/3 SJTW) and compression fitting

## DIMENSIONS:

4-1/4"(W) x 4-2/3"(H) x 1-1/2"(D)

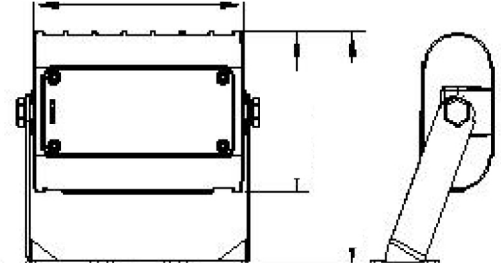

## LF3-15CW-TR LF3-15WW-TR

### LED Flood Lights 3 Series With Trunnion

Ideal for general site lighting, alleys, loading docks, doorways, pathway, parking areas. Replace existing HID flood lights/wall packs. Great for use with motion sensors or other instant on/off controls. Solid state lighting technology for long life, low maintenance and high efficiency.

#### ELECTRICAL SPECIFICATIONS:

- Voltage: 100-277VAC 50/60Hz
- Wattage: 15W
- Input current: 0.18A Max.
- Other wattages: 30W, 50W
- Power factor: PF>0.90
- Output voltage: 36-60VDC
- Output current: 0.25A
- Driver efficiency: 88%

#### HOUSING SPECIFICATIONS:

- Die-cast aluminum with powder coat finish (Dark Bronze)
- Operating temperature: -30 —+40 °C
- Lifespan: 50000Hrs.
- IP rating: IP65, Wet Locations
- 100% dip-tested under load
- Main Structure: aluminum + Optical Lens
- Storage temperature humidity: -40 —+80 °C , 10—90% RH

#### CERTIFICATIONS:



MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
LF3-15CW-TR	15W	100~277v	1500 LM	5000K
LF3-15WW-TR	15W	100~277v	1467 LM	3000K

#### LIGHTING SPECIFICATIONS:

- Not dimmable
- LED type/brand: SMD 3030/ Philips Lumileds LEDs
- Total lumens: 1500lm and 1467lm
- Color temperature: 3000K / 4000K / 5000K / 5700K
- Color rendering index: >80
- Beam angle: 120x90°
- Luminance: 1450 Lm (DLC)
- Luminous Efficiency: 96 Lm/W (DLC )
- LED quantity: 18 PCS
- LED efficacy: 120Lm/W

#### SAFETY & EMC:

- Safety norms: UL1598, UL8750, EN60598, EN61347-2-13, EN62031, EN62471
- Withstand voltage: I/P-FG: 2121VDC
- Grounding resistance: ≤0.5Ω,OK
- Electromagnetic compatibility: EN55015, EN61000-2-3, EN61000-3-3, EN61547
- Net weight: 24lbs
- Gross weight: 26lbs
- Packing size: inner box: L150\*W50\*H175  
master carton: L465\*W365\*H170

#### WARRANTY: 7 years

