

LF3-HL SERIES Outdoor Lighting

LF3-HL-30W-30K-D-KN
LF3-HL-30W-40K-D-KN
LF3-HL-30W-50K-D-KN




Customer Name: _____

Project Name: _____

Note: _____

Type: _____

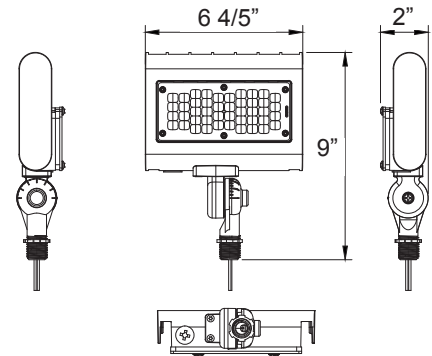

9"(H) x 6 4/5"(W) x 2"(D)

Ideal for general site lighting, alleys, loading docks, doorway, pathway, and parking areas.

Features

- DLC Premium & LED High-Lumen Floor lights
- LF3 0-10 Dimming Flood Light Series With 1/2" Knuckle
- 70,000 Hours Rated Life
- 7-Year Warranty
- Lens: TYPE II, III and IV Optic Lens

Technical Specifications

Electrical:

- Voltage: 120~277VAC/50~60 Hz
- Wattage: 30W
- Power factor: >0.9
- Efficacy: 120 LPW

Mechanical:

- Die-cast Aluminum Housing with Powder Coat Finish (Dark Bronze)
- Solid State Lighting Technology for Long Life, No Maintenance Needed and High-Efficiency
- High Conductive Aluminum LED Board
- IP Rating: IP65
- Operating Temperature: -40°F to 104°F
- Suitable for Wet Locations

Lighting:

- Dimming: 0~10V dimmable
- Optic Lens Type: II
- LED: Philips Lumileds Luxeon 3030 High Flux LED
- Cord Type: 6' SJTW 18/3 AWG cable
- Total Lumens: 3600LM
- Color Temperature: 3000K/ 4000K/ 5000K
- Color Rendering Index: ≥ 82
- Beam Angle: 120°x90°

Applications:

- Ideal for general site lighting, alleys, loading docks, doorway, pathway and parking areas.
- Replace existing HID flood lights/ wall packs
- Great for use with motion sensors or other bi-level controls



Other Models:

- 30K | 6100LM | LF3-HL-50W-30K-D-KN
- 40K | 6100LM | LF3-HL-50W-40K-D-KN
- 50K | 6100LM | LF3-HL-50W-50K-D-KN




Photometrics: LF3-HL-30W-D-KN

TYPE II

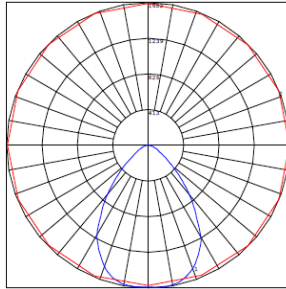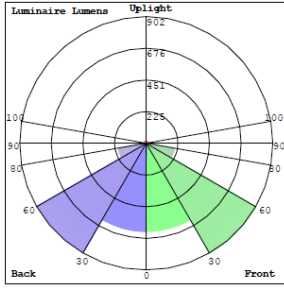

BUD Rating: B2-U2-G1

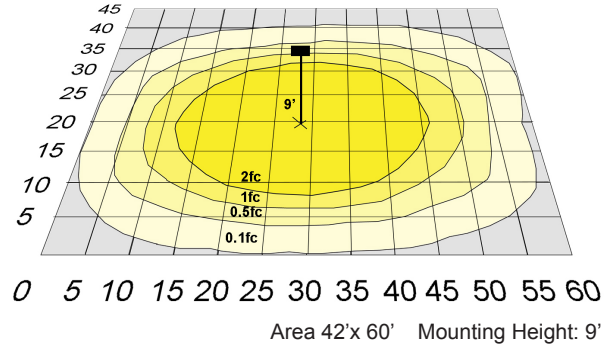

Other Views:



Front View



Side View



Back View

Performance Table: LF3-HL-30W-D-KN

| MODEL NO. | Wattage | Voltage | Lumens | Color Temp. | BUG Rating | LPW |
|---------------------|---------|----------|--------|-------------|------------|-----|
| LF3-HL-30W-30K-D-KN | 30W | 120~277V | 3600LM | 3000K | B2-U2-G1 | 120 |
| LF3-HL-30W-40K-D-KN | 30W | 120~277V | 3600LM | 4000K | B2-U2-G1 | 120 |
| LF3-HL-30W-50K-D-KN | 30W | 120~277V | 3600LM | 5000K | B2-U2-G1 | 120 |

Sample Ordering

Model Wattage Color Temp.

LF3 - HL - 30W - - D - KN

30K = 3000K
40K = 4000K
50K = 5000K

Accessories Options

Blank = No Option For Accessories
LF3-SH1 = Shroud for LF3 30W Reversible
LF3-SH1FG = Full-Glare Shroud for LF3 30W

Example:

1.LF3-HL-30W-30K-D-KN (For LF3 30W 3000K fixture 120~277V)
2.LF3-HL-30W-30K-D-KN (For LF3 30W 3000K fixture 120~277V)
LF3-SH1 (For Shroud for LF3 30W Reversible)

ACCESSORIES OPTIONS



LF3-SH1
Shroud (Reversible)



LF3-SH1FG
Full-Glare Shroud

