




LF4-100CW-SF
LF4-100WW-SF

DIMENSIONS:

16-1/2"(H) x 11"(W) x 4-1/8"(D)

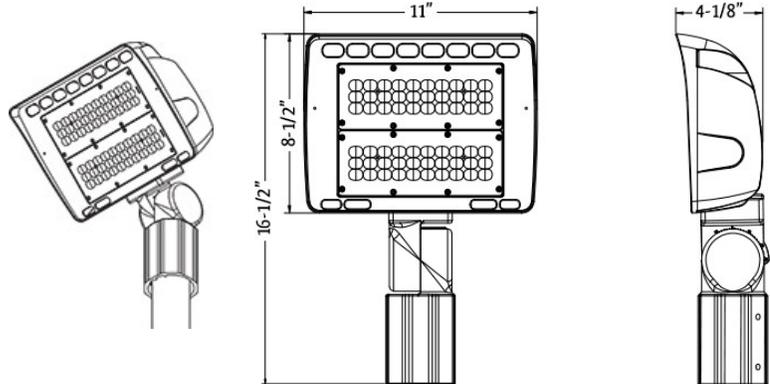

**LF4 ARCHITECTURAL SERIES LED FLOOD LIGHT
 WITH SLIP FITTER**

MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
LF4-100CW-SF	100W	120~277V AC	11200 LM	5000K
LF4-100WW-SF	100W	120~277V AC	11200 LM	3000K

Ideal for general site lighting, alleys, loading docks, doorway, pathway and parking areas. Great for use with motion sensors or other instant on/off controls.

ELECTRICAL SPECIFICATIONS:

- Voltage: 120-277VAC 50/60Hz
- Wattage: 100W
- Input current: 1.5A Max
- Other wattages: 80W, 150W
- Power factor: >0.95
- Efficacy: 115LM/W

HOUSING SPECIFICATIONS:

- Die-cast aluminum with powder coat finish (Dark Bronze)
- Operating temperature: -40°F ~ 104°F
- Lifespan: 70000 Hrs.
- IP rating: IP65, Wet Locations
- High light transmittance, anti-UV & fire resistant PC lens

LIGHTING SPECIFICATIONS:

- Dimmable: 0~10V Dimmable
- LED type/brand: Philips Lumileds LEDs / SMD 3030
- Total lumens: 11200LM
- Color temperature: 3000K / 5000K
- Color rendering index: >82
- Beam angle: 90° x 120°

WARRANTY: 7 years

CERTIFICATIONS: UL, DLC



Rev. 2020-11-20



LF4-100CW-SF
LF4-100WW-SF



**LF4 ARCHITECTURAL SERIES LED FLOOD LIGHT
 WITH SLIP FITTER**

MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
LF4-100CW-SF	100W	120~277V AC	11200 LM	5000K
LF4-100WW-SF	100W	120~277V AC	11200 LM	3000K

CERTIFICATIONS: UL, DLC



PHOTOMETRICS:

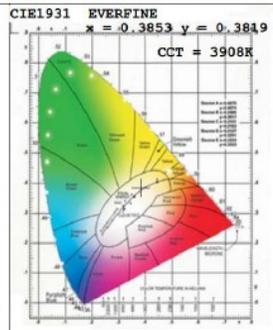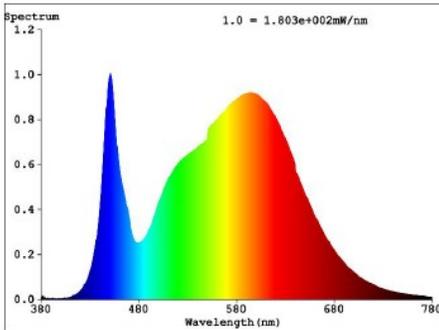

Illuminance at a Distance

Center Beam fc	Beam Width	
17.0ft	15.29 fc	31.2 ft 55.4 ft
34.0ft	3.82 fc	62.5 ft 110.8 ft
51.0ft	1.70 fc	93.7 ft 166.2 ft
68.0ft	0.96 fc	124.9 ft 221.6 ft
85.0ft	0.61 fc	156.1 ft 277.0 ft
102.0ft	0.42 fc	187.4 ft 332.4 ft

■ Vert. Spread: 85.1°
 ■ Horiz. Spread: 116.9°

