


JOB NAME: _____

DATE: _____

TYPE: _____

DIMENSIONS:

21.7"(H) x 14.2"(W) x 4.7"(D)

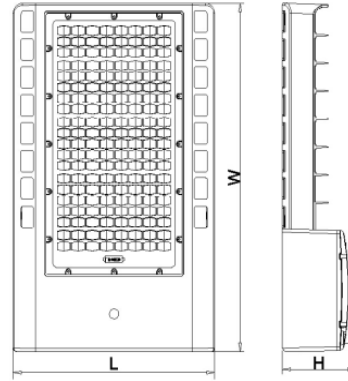

LF5-380CW-480V

LF5 SERIES WITH MOUNTING OPTIONS

Ideal for general site lighting, alleys, loading docks, doorway, pathway and parking areas. Great for use with motion sensors or other instant on/off controls.

ELECTRICAL SPECIFICATIONS:

- Voltage: 347-480V
- Wattage: 380 W
- Power factor: >0.9~0.97
- Efficacy: UP TO 110 LM/W

HOUSING SPECIFICATIONS:


- Die-Cast Aluminum
- Powder Coat Finish (Dark Bronze)
- Aluminum LED board
- Operating temperature: -40°F to 104°F
- Lifespan: 70,000 hr.
- IP Rating: IP65

CERTIFICATIONS: UL, DLC



MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
LF5-380CW-480V	380W	120~277V AC	46000 LM	5000K

PHOTOMETRICS:

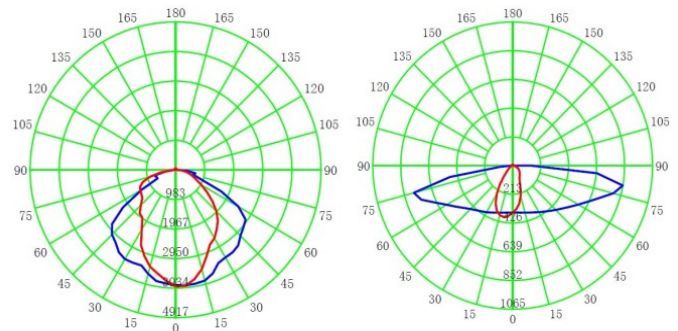

LIGHTING SPECIFICATIONS:

- Dimming: 0~10V dimmable
- LED: TIR optic lens — TYPE III (TYPE II & IV by request)
- Total lumens: 46000 LM
- Color temperature: 5000K
- Color rendering index: 82~84

WARRANTY: 7 years

