




DIMENSIONS:

47.24"(L) x 2.62"(W) x 2.7(H)

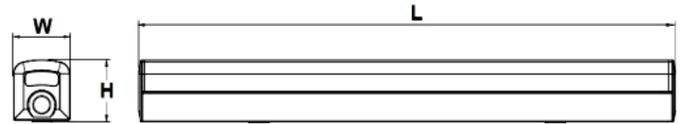

LSS-4FT-25W-MCT

LED MULTI COLOR TEMPERATURE STRIP LIGHT

Ideal for one-for-one replacement of conventional lighting systems such as HID and fluorescent. Applications include manufacturing, warehousing and other large indoor spaces

ELECTRICAL SPECIFICATIONS:

- Voltage: 120~277 VAC/50~60 Hz
- Wattage: 25W
- Efficacy: 130LM/W

HOUSING SPECIFICATIONS:

- Linkable
- Mounting: Ceiling Mount, Suspension Mount
- Operating temperature: -40°F ~ 122°F
- Suitable for Damp locations

CERTIFICATIONS: UL, DLC



MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
LSS-4FT-25W-MCT	25W	100~277V AC	3250LM	MCT

OPTIONAL ACCESSORIES:



MODEL	DESCRIPTION
LSS-CB	COUPLING BRACKET
SCL-CS	ADJ. 1/16" 6FT. SUSPENSION KIT WITH SINGLE-CONNECTOR KEY HOLE SET + 2 T-BAR CLIPS + 1 CABL BUSHING + 3 PLASTIC TIE STRAPS
SCL-GSY10	HEAVY-DUTY ADJUSTABLE 10 FT. 1/16" SUSPENSION KIT WITH Y-CONNECTOR & LOOP GRIPPER & HOOKS
SCL-GSY20	HEAVY-DUTY ADJUSTABLE 20 FT. 1/16" SUSPENSION KIT WITH Y-CONNECTOR & LOOP GRIPPER & HOOKS

LIGHTING SPECIFICATIONS:

- Dimming: 0~10V dimmable
- Total lumens: 3250LM
- Color temperature: MCT(3500K,4000K,5000K)

WARRANTY: 5 years

