

LSW SERIES Outdoor Lighting

LSW-30WW-PC
LSW-30NW-PC
LSW-30CW-PC



Selection:




WESTGATE
THE FUTURE IS HERE...AND IT'S QUITE BRIGHT!

Customer Name: _____

Project Name: _____

Note: _____

Type: _____

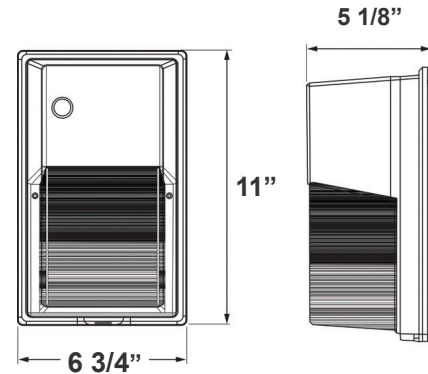

11"(L) x 6 3/4"(W) x 5 1/8"(H)

LED Non-Cutoff Wall Pack with Photocell is ideal for general site lighting, loading docks, doorway, pathway and parking areas.

Features

- Back plate: Die-cast aluminum
- Threaded 1/2" Knockout Provided on Top Section of the Back
- Polycarbonate Housing & Lens
- 7-Year Warranty

Technical Specifications

Electrical:

- Voltage: 120-277VAC 60Hz
- Wattage: 30W
- Power Factor: >0.95
- Efficacy: 90/ 93/ 97 LPW
- Includes Pre-wired Photo Electric Control (Dusk to Dawn Photocell), 120 Volt, Removable
- Photocell Response Time: Maximum 3 Seconds

Mechanical:

- Back plate: Die-Cast Aluminum with Mounting/Gasket Installed
- Threaded 1/2" Knockout Provided on Top Section of the Back
- Polycarbonate Housing & Lens
- Non-Cutoff Optics Ideal for Maximum Light Distribution
- Operating Temperature: -4°F -104°F
- Wet Location
- 7-Year Warranty
- IP54

Lighting:

- LED Type/Brand: SMD 3030/ Philips Lumileds LEDs
- Front: Polycarbonate Lens and Housing
- Total Lumens: 2700LM/ 2800LM/ 2900LM
- Color Temperatures: 3000K/ 4000K/ 5000K
- Color Rendering Index: CRI ≥ 80
- Beam Angle: 90° x 110°
- Rated life: 70,000 Hrs

Applications:

- Ideal for general site lighting, loading docks, doorway, pathway and parking areas.

Other Models:

- 20W | 2000LM | LSW-20WW-PC
- 20W | 2050LM | LSW-20NW-PC
- 20W | 2100LM | LSW-20CW-PC





Phone: (877) 805-2252 | Fax: (877) 805-2252
www.westgatemfg.com | www.westgatecontrols.co




WG-Z9-Z9-Z2

Photometrics: LSW-30W

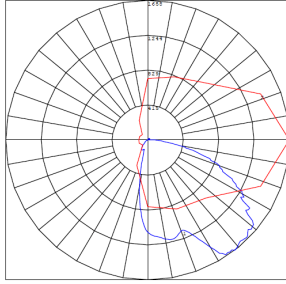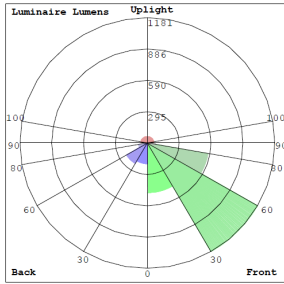

BUD Rating: B1-U3-G1

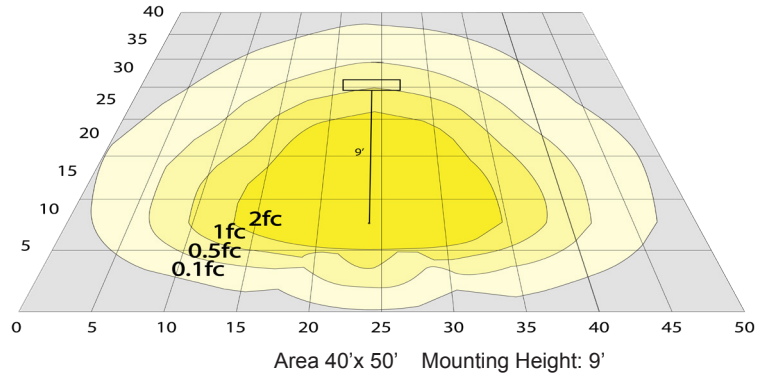

Other Views:




Side View



Front View



Back View

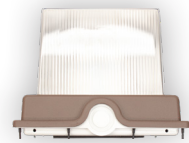

Bottom View

Performance Table: LSW-30W

MODEL NO.	Wattage	Voltage	Lumens	Color Temp.	BUG Rating	LPW
LSW-30WW-PC	30W	120~277V	2700LM	3000K	B1-U3-G1	90
LSW-30NW-PC	30W	120~277V	2800LM	4000K	B1-U3-G1	93
LSW-30CW-PC	30W	120~277V	2900LM	5000K	B1-U3-G1	97

Sample Ordering

Model	Wattage	Color Temp.	Feature
LSW	-	30	-
		WW = 3000K	
		NW = 4000K	
		CW = 5000K	
			PC

Factory-Installed Options:

Blank = No Option For Accessories

OPT-NOPC = REMOVE PHOTOCELL

OPT-SEN-SLPIR = EXTERNAL SECURITY LIGHT TYPE PIR MOTION SENSOR

FACTORY-INSTALLED OPTIONS:



OPT-SEN-SLPIR

Example:

1. LSW-30CW-PC

(FOR LSW 30W 5000K FIXTURE 120-277V)

2. LSW-30CW-PC
OPT-NOPC

(FOR LSW 30W 5000K FIXTURE 120-277V)
(REMOVE PHOTOCELL)

