

GOODYEAR

HEAVY DUTY BLADE
Limpiaparabrisas de servicio pesado
Essuie-glace robuste

Blades with heavy-duty, riveted frames cover sizes 20" - 40" for trucks, buses, and RVs

Los tamaños del limpiaparabrisas de servicio pesado varían de 20 a 40 pulgadas para camiones, autobuses y RVs

Les tailles de l'essuie-glace robuste varient de 20 à 40 pouces pour les camions, les autobus et les véhicules récréatifs

ROBUST ENOUGH FOR ANY JOB

Lo suficientemente robusto para cualquier trabajo

Assez robuste pour tout travail



Model 711

Model 713

Model 717

Model 718



Saddle Pin
Perno de monte ancho
Goupille de selle large



Hook Arm
Brazo de gancho
Crochet bras



Wide Saddle Pin
Perno de monte
Goupille de selle



Side Pin
Perno lateral
Goupille latérale

**Compatible
Arm Types**

**Tipos de brazos compatibles
Types de bras compatibles**



Made in USA
Hecho en USA
Fabriqué aux USA

SPACER GUIDE

Guía del Espaciador | Guide d'Entretoise




6.4 mm Spacer
6.4 mm Espaciador
6.4 mm Entretoise

PART NUMBER	SIZE		BRIDGE WIDTH WITHOUT SPACER		BRIDGE WIDTH WITH SPACER		BOLT & NUT
	in	mm	in	mm	in	mm	
711-11	11	280	0.2	5.1	0.25	6.4	3
711-12	12	305	0.2	5.1	0.25	6.4	3
711-13	13	330	0.2	5.1	0.25	6.4	3
711-14	14	355	0.2	5.1	0.25	6.4	3
711-15	15	380	0.2	5.1	0.25	6.4	3
711-16	16	405	0.2	5.1	0.25	6.4	3
711-17	17	430	0.2	5.1	0.25	6.4	3
711-18	18	455	0.2	5.1	0.25	6.4	3
711-19	19	485	0.2	5.1	0.25	6.4	3
711-20	20	510	0.2	5.1	0.25	6.4	3
711-21	21	535	0.2	5.1	0.25	6.4	3
711-22	22	560	0.2	5.1	0.25	6.4	3




6.4 mm Spacer
6.4 mm Espaciador
6.4 mm Entretoise

PART NUMBER	SIZE		BRIDGE WIDTH WITHOUT SPACER		BRIDGE WIDTH WITH SPACER		BOLT & NUT
	in	mm	in	mm	in	mm	
713-11	11	280	0.2	5.1	0.25	6.4	3
713-12	12	305	0.2	5.1	0.25	6.4	3
713-13	13	330	0.2	5.1	0.25	6.4	3
713-14	14	355	0.2	5.1	0.25	6.4	3
713-15	15	380	0.2	5.1	0.25	6.4	3
713-16	16	405	0.2	5.1	0.25	6.4	3
713-17	17	430	0.2	5.1	0.25	6.4	3
713-18	18	455	0.2	5.1	0.25	6.4	3
713-19	19	485	0.2	5.1	0.25	6.4	3
713-20	20	510	0.2	5.1	0.25	6.4	3
713-21	21	535	0.2	5.1	0.25	6.4	3
713-22	22	560	0.2	5.1	0.25	6.4	3
713-24	24	610	0.2	5.1	0.25	6.4	3
713-26	26	660	0.2	5.1	0.25	6.4	3
713-28	28	710	0.2	5.1	0.25	6.4	3

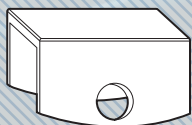


13.6mm Spacer
13.6 mm Espaciador
13.6 mm Entretoise

PART NUMBER	SIZE		BRIDGE WIDTH WITHOUT SPACER		BRIDGE WIDTH WITH SPACER 1		BRIDGE WIDTH WITH SPACER 2		BOLT & NUT
	in	mm	in	mm	in	mm	in	mm	
717-20	20	510	0.5	12.7	0.535	13.6	0.64	16.3	5
717-22	22	560	0.5	12.7	0.535	13.6	0.64	16.3	5
717-24	24	610	0.5	12.7	0.535	13.6	0.64	16.3	5
717-26	26	660	0.5	12.7	0.535	13.6	0.64	16.3	5
717-28	28	710	0.5	12.7	0.535	13.6	0.64	16.3	5
717-32	32	815	0.5	12.7	0.535	13.6	0.64	16.3	5

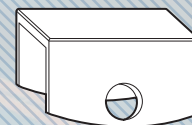


 16.3 mm Spacer
16.3 mm Espaciador
16.3 mm Entretoise



23 mm Spacer
23 mm Espaciador
23 mm Entretoise

PART NUMBER	SIZE		ARM TYPE	6 MM BOLT & NUT		8 MM BOLT & NUT	
	in	mm		spacer size		spacer size	
718-32	32	815	Saddle Pin	23 mm	23 mm	25 mm	
718-36	36	915	Saddle Pin	23 mm	23 mm	25 mm	
718-37	36	915	6 x 16 Hook	N/A	N/A	N/A	
718-40	40	1015	Saddle Pin	23 mm	23 mm	25 mm	
718-41	40	1015	6 x 16 Hook	N/A	N/A	N/A	

 

25 mm Spacer
25 mm Espaciador
25 mm Entretoise