

LED 3 Multi Wattage Multi CCT 4 Foot Wrap Around Light



32W / 40W / 48W



Suction cup to assist in lifting wrap cover included

CONSTRUCTION:

22-gauge metal housing with matte white finish. PMMA cover lens.

OPTICAL SYSTEM:

Samsung 2835 LED chips. Frosted lens. 110° beam angle.

WARRANTY:

5-year limited warranty. Actual performance may differ as a result of end-user environment and application.

ELECTRICAL:

Available as 120-277V input. -20°C to 50°C, -4°F to 122°F

INSTALLATION & MOUNTING:

Suspension or surface mounting options.

CONTROLS & DIMMING:

0-10V dimming comes standard.

FEATURES

- Default Wattage: 48W
- Default CCT: 5,000K
- IP20 rated
- 50,000 hours lifetime

SUITABLE APPLICATIONS

- Distribution Centers
- Aisles
- Corridors
- Restrooms
- Commercial Facilities
- Warehouses
- Stairwells

DLC Product ID:


- LOC-4FTWA-MW(32/40/48)MCCT(35/40/50)D - S-YCUFDJ



LOC-4FTWA-MW(22/28/34/44)MCCT(35/40/50)D

WATTAGE SELECTABLE	CCT SELECTABLE	LUMENS	EFFICACY	VOLTAGE	CRI	POWER FACTOR	THD	REPLACES
32W	3500K / 4000K / 5000K	3,680LM	115LM/W	120-277V	81.6	0.969	17.2%	
40W	3500K / 4000K / 5000K	4,600LM	115LM/W	120-277V	81.6	0.969	17.2%	
48W	3500K / 4000K / 5000K	5,814.72LM	120.5LM/W	120-277V	81.6	0.969	17.2%	

MEASUREMENTS

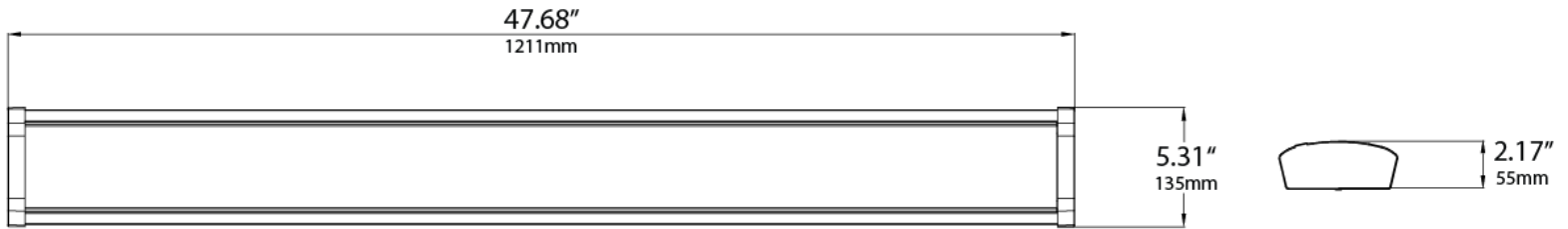

MODEL	QUANTITY	WEIGHT	UPC CODE
LOC-4FTWA-MW(32/40/48)MCCT(35/40/50)D	1	lbs	00810050942