

## LED Multi Wattage Multi CCT Post Top Light

### CONSTRUCTION:

Polyester powder-coated finish

### OPTICAL SYSTEM:

Philips Lumileds 3030 LED chips. 120° beam angle.

### WARRANTY:

5-year limited warranty. Actual performance may differ as a result of end-user environment and application.

### ELECTRICAL:

Available as 120-277V input. -20°C to 50°C, -4°F to 122°F

### INSTALLATION & MOUNTING:

Pole mounting – Suitable for 3" poles

### CONTROLS & DIMMING:

0-10V dimming comes standard.

### FEATURES

- Default Wattage: 150W
- Default CCT: 5,000K
- IP65 rated
- Type 5 lens
- Rust & corrosion proof
- No lead or mercury
- 50,000 hours lifetime

### SUITABLE APPLICATIONS

- Area lighting
- Parking decks
- Auto dealerships
- High masts
- Housing complexes
- Shopping malls
- Sporting complexes
- Parks and Recreational areas
- Municipal lots

### DLC Product ID:

- LOC-PT-MW(60/80/100/150)MCCT(30/40/50)DLV – S-84G27F



### OPTIONAL ACCESSORIES:



Motion Sensor  
LOC-ANT-5-4T  
(Compatible with remote control)



Remote Control  
LOD-RC-100




Photocell (Daylight Sensor)  
LOC-SK-101-4T  
(Not compatible with remote control)

| BUG RATING | EPA  |
|------------|------|
| B4-U1-G1   | 1.96 |

LED Multi Wattage Multi CCT Post Top Light

| LOC-PT-MW(60/80/100/150)MCCT(30/40/50)DLV |                       |            |            |          |     |              |     |                |
|-------------------------------------------|-----------------------|------------|------------|----------|-----|--------------|-----|----------------|
| WATTAGE SELECTABLE                        | CCT SELECTABLE        | LUMENS     | EFFICACY   | VOLTAGE  | CRI | POWER FACTOR | THD | REPLACES       |
| 60W                                       | 3000K / 4000K / 5000K | 8,251.8LM  | 137.53lm/W | 120-277V | 71  | 0.974        | 8%  | 50W – 100W HID |
| 80W                                       | 3000K / 4000K / 5000K | 11,002.4LM | 137.53lm/W | 120-277V | 71  | 0.974        | 8%  | 50W – 100W HID |
| 100W                                      | 3000K / 4000K / 5000K | 13,753LM   | 137.53lm/W | 120-277V | 71  | 0.974        | 8%  | 50W – 100W HID |
| 150W                                      | 3000K / 4000K / 5000K | 20,897LM   | 137.53lm/W | 120-277V | 71  | 0.974        | 8%  | 50W – 100W HID |

MEASUREMENTS

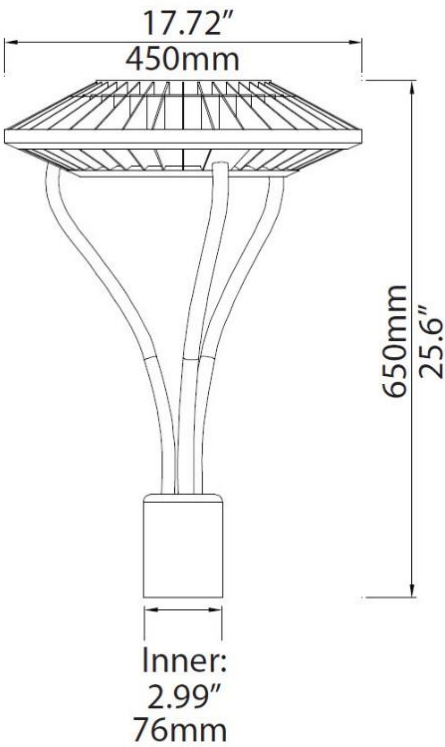

| MODEL                                     | QUANTITY | WEIGHT | UPC CODE       |
|-------------------------------------------|----------|--------|----------------|
| LOC-PT-MW(60/80/100/150)MCCT(30/40/50)DLV | 1        | lbs    | 00810050941310 |

