

Date: _____ Location: _____
 Product: _____ Project: _____
 Quantity: _____ Catalog #: _____



70W / 90W / 110W or 145W / 160W / 175W



180W / 200W / 220W or 290W / 320W / 350W or
360W / 400W / 440W



LED Foldable Linear High Bay Family Series

CONSTRUCTION:

Die formed galvanized steel, white paint.
 Isolated driver with wide voltage input option.
 Frosted PMMA lens. (Clear lens special order)

OPTICAL SYSTEM:

Lumileds 2835 LED chips. 120° beam angle options.

WARRANTY:

5-year limited warranty. Actual performance may differ as a result of end-user environment and application.

ELECTRICAL:

Available as 120-277V input.

-20°C to 40°C, -4°F to 104°F

INSTALLATION & MOUNTING:

Surface mount, hanging hook or pendant mount.

CONTROLS & DIMMING:

0-10V dimming comes standard. Suitable for use with LED dimmers.

FEATURES

- Default Wattage:
 - 110W
 - 175W
 - 220W
 - 350W
 - 440W
- Foldable sides
- IP40 rated
- DC 12V auxiliary
- Easy installation and maintenance
- 50,000 hours lifetime

SUITABLE APPLICATIONS

- Warehouses
- Factories
- Supermarkets
- Logistic Centers
- Exhibition Halls



OPTIONAL ACCESSORIES:



Motion Sensor
 LOC-ANT-5-4T
 (Compatible with remote control)



Remote Control
 LOD-RC-100



Emergency Driver
 LOC-EMDR-15W-050

MOUNTING OPTIONS:



Pendant Mount



Chain & Hook

LED Foldable Linear High Bay Family Series

LOC-2FTFLHB-MW(70/90/110)50KD

WATTAGE SELECTABLE	CCT	LUMENS	EFFICACY	VOLTAGE	CRI	POWER FACTOR	THD	REPLACES
70W	5000K	9,450LM	150lm/W	120-277V	80	0.9	20%	400W HID
90W	5000K	12,150LM	150lm/W	120-277V	80	0.9	20%	400W HID
110W	5000K	14,850LM	150lm/W	120-277V	80	0.9	20%	400W HID

LOC-2FTFLHB-MW(145/160/175)50KD

WATTAGE SELECTABLE	CCT	LUMENS	EFFICACY	VOLTAGE	CRI	POWER FACTOR	THD	REPLACES
145W	5000K	19,575LM	150lm/W	120-277V	80	0.9	20%	400W – 600W HID
160W	5000K	21,600LM	150lm/W	120-277V	80	0.9	20%	400W – 600W HID
175W	5000K	23,625LM	150lm/W	120-277V	80	0.9	20%	400W – 600W HID

LOC-4FTFLHB-MW(180/200/220)50KD

WATTAGE SELECTABLE	CCT	LUMENS	EFFICACY	VOLTAGE	CRI	POWER FACTOR	THD	REPLACES
180W	5000K	24,300LM	150lm/W	120-277V	80	0.9	20%	575W – 1000W HID
200W	5000K	27,000LM	150lm/W	120-277V	80	0.9	20%	575W – 1000W HID
220W	5000K	29,700LM	150lm/W	120-277V	70	0.9	20%	575W – 1000W HID

LOC-4FTFLHB-MW(290/320/350)50KD

WATTAGE SELECTABLE	CCT	LUMENS	EFFICACY	VOLTAGE	CRI	POWER FACTOR	THD	REPLACES
290W	5000K	39,150LM	150lm/W	120-277V	80	0.9	20%	1000W – 1,400W HID
320W	5000K	43,200LM	150lm/W	120-277V	80	0.9	20%	1000W – 1,400W HID
350W	5000K	47,250LM	150lm/W	120-277V	80	0.9	20%	1000W – 1,400W HID

LOC-4FTFLHB-MW(360/400/440)50KD




WATTAGE SELECTABLE	CCT	LUMENS	EFFICACY	VOLTAGE	CRI	POWER FACTOR	THD	REPLACES
360W	5000K	48,600LM	150lm/W	120-277V	80	0.9	20%	1400W – 1700W HID
400W	5000K	54,000LM	150lm/W	120-277V	80	0.9	20%	1400W – 1700W HID
440W	5000K	59,400LM	150lm/W	120-277V	80	0.9	20%	1400W – 1700W HID

FOLDABLE STYLE







MEASUREMENTS





LOC-2FTFLHB-MW(70/90/110)50KD

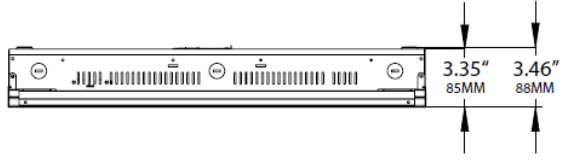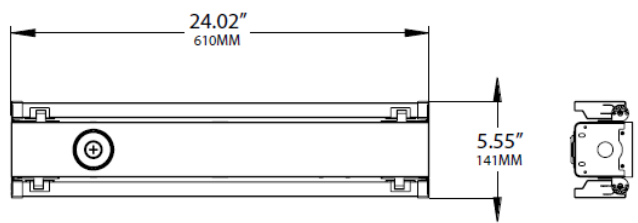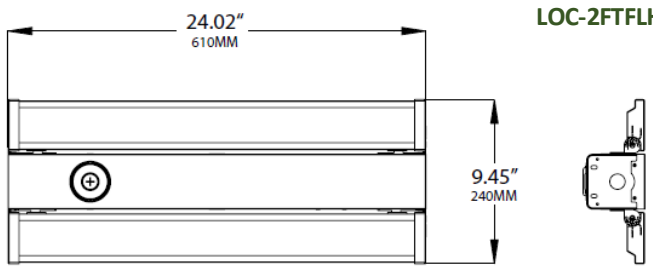

LOC-2FTFLHB-MW(145/160/175)50KD

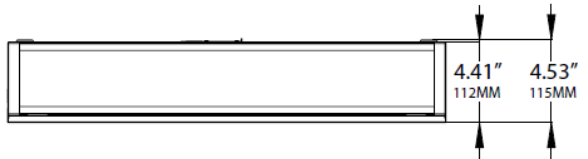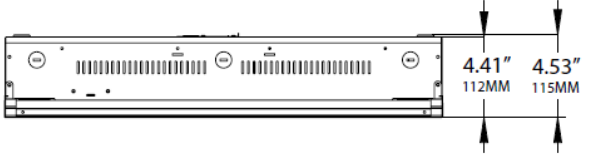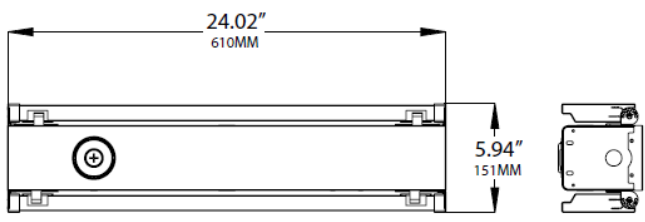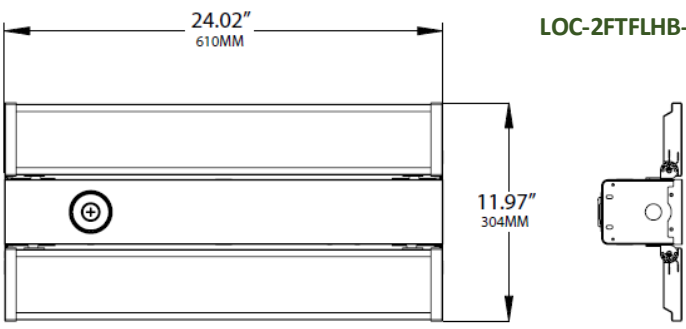

LOC-4FTFLHB-MW(180/200/220)50KD / LOC-4FTFLHB-MW(290/320/350)50KD / LOC-4FTFLHB-MW(360/400/440)50KD

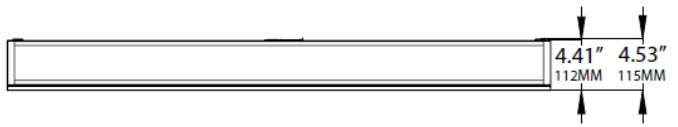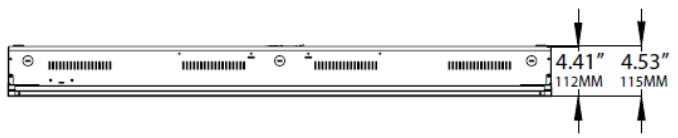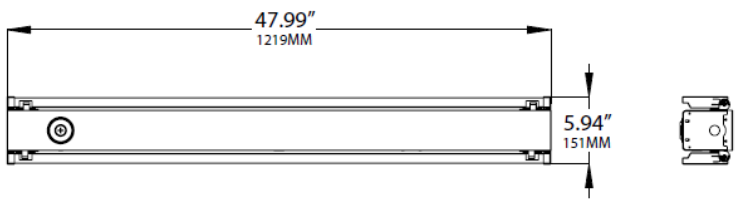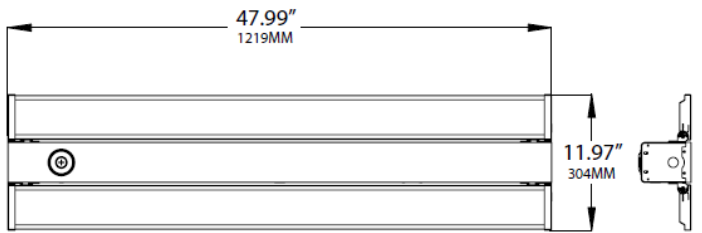

MODEL	QUANTITY	WEIGHT	UPC CODE
LOC-2FTFLHB-MW(70/90/110)50KD	1	7.56 lbs	00810050942966
LOC-2FTFLHB-MW(145/160/175)50KD	1	10.27 lbs	00810050942973
LOC-4FTFLHB-MW(180/200/220)50KD	1	16.07 lbs	00810050942980
LOC-4FTFLHB-MW(290/320/350)50KD	1	19.09 lbs	00810050942997
LOC-4FTFLHB-MW(360/400/440)50KD	1	19.09 lbs	00810050943000