

LED Multi CCT Round Panel Down Light

CONSTRUCTION:

Plastic trim with metal board back plate and frosted lens.

OPTICAL SYSTEM:

SiRise Micro LED chips. 120° Beam Angle.

WARRANTY:

5-year limited warranty. Actual performance may differ as a result of end-user environment and application.

ELECTRICAL:

120V input.

Operating Temperature: -20°C to 40°C, -4°F to 104°F

INSTALLATION & MOUNTING:

Surface mount.

DIMMING:

Triac Dimming.

FEATURES

- IP20 rated
- 5CCT selectable:
 - 2,700K
 - 3,000K
 - 3,500K
 - 4,000K
 - 5,000K
- 15" cord connector to Jbox
- Easy installation and maintenance
- Corrosion and rust proof
- 50,000 hours lifetime

SUITABLE APPLICATIONS

- Kitchens
- Bedrooms
- Bathrooms
- Corridors
- Hallways
- Museums

Energy Star ID:


- LOC-4UTRP-9WMCCT(27/30/35/40/50)D-C90 – 2374648
- LOC-6UTRP-14WMCCT(27/30/35/40/50)D-C90 - 2374660



4" 9W



6" 14W

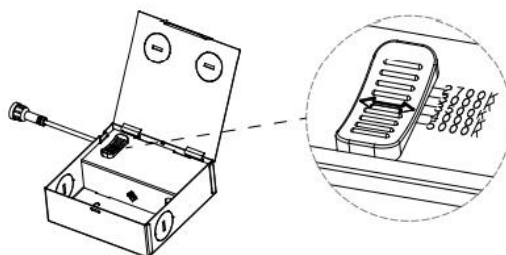

LOC-4UTRP-9WMCCT(27/30/35/40/50)D-C90


WATTAGE	CCT SELECTABLE	LUMENS	EFFICACY	VOLTAGE	CRI	POWER FACTOR	REPLACES
9W	2700K / 3000K 3500K / 4000K / 5000K	650LM	72.2lm/W	120V	94	1.0	65W

LOC-6UTRP-14WMCCT(27/30/35/40/50)D-C90


WATTAGE	CCT SELECTABLE	LUMENS	EFFICACY	VOLTAGE	CRI	POWER FACTOR	REPLACES
14W	2700K / 3000K 3500K / 4000K / 5000K	1,100LM	78.6lm/W	120V	93	1.0	85W

MEASUREMENTS

4" 9W

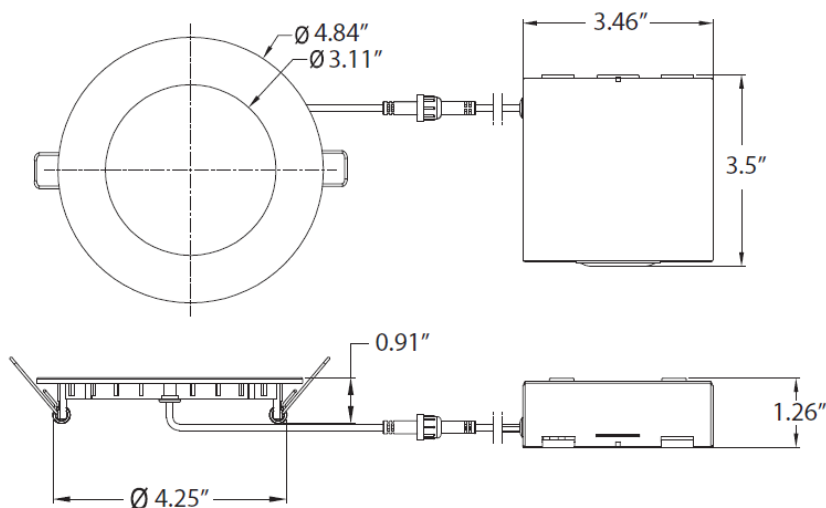

6" 14W

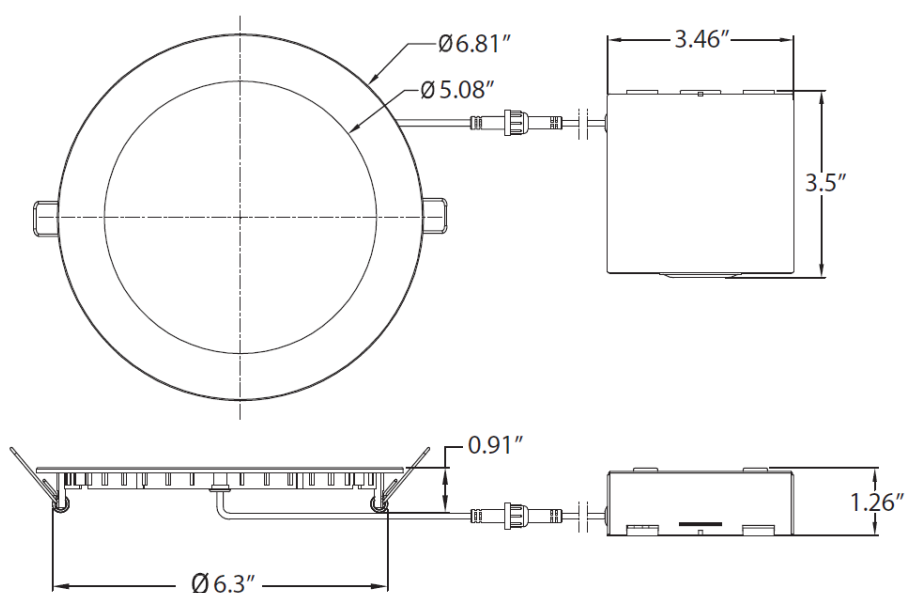

MODEL	QUANTITY	WEIGHT	UPC CODE
LOC-4UTRP-9WMCCT(27/30/35/40/50)D-C90	1	0.70 lbs	00810050940580
LOC-6UTRP-14WMCCT(27/30/35/40/50)D-C90	1	0.90 lbs	00810050940597