

KIP740/742/743/746/
747/748/749/755(S)-EUK



Mounting Pattern
200 x 200 up to
400 x 600mm



Max Load
75lb
(34kg)

In-Wall Kiosk Enclosure

Fits 40", 42", 43", 46", 47", 48", 49" and 55" Displays
up to 3.10" (78mm) Thick

With a profile less than 1" thin, Peerless-AV's In-Wall Kiosk Enclosure offers a sleek solution to display engaging, digital signage content. Complete with extending mount arms and a removable front cover, this kiosk offers easy installation and access to internal components when maintenance is needed. To ensure proper airflow into the kiosk enclosure, a powerful, thermostat controlled fan is included. Available in portrait or landscape orientation, Peerless-AV's In-Wall Kiosk Enclosures are ideal for any indoor application - from hospitality, retail, entertainment venues and more.

- Accommodates displays 3.10" (78mm) thick while still fitting within standard wood stud walls
- VESA® 200 x 200 up to 400 x 600mm compatible
- Thermostat controlled circulation fans ensure proper airflow into the kiosk
- Pre-assembled to simplify installation of the entire solution
- Supports wide range of aesthetic options including glass/acrylic, multiple colors, vinyl wraps, etc. to best match environment or promote brand strategy
- Custom sizes available for smaller and larger displays



REMOVABLE FRONT COVER & PULL-OUT MOUNT

Allows easy installation and maintenance of display and other internal components

8-WAY MICRO ADJUSTMENT

Provides quick vertical, horizontal and depth adjustment to quickly position display in kiosk window for flush alignment



LOW-PROFILE DESIGN

Extends 1" (25mm) away from the wall which meets the Americans with Disabilities Act (ADA)

Portrait Model



Landscape Models Available



RoHS
2009/100/EC



TAA
COMPLIANT

Model Numbers

WARRANTY: 5 years on metal components, 1 year on electronic components

Portrait Models:

KIP740(-S)-EUK In-Wall Kiosk Enclosure fits 40" Displays up to 3.10" (78mm) Thick
KIP742(-S)-EUK In-Wall Kiosk Enclosure fits 42" Displays up to 3.10" (78mm) Thick
KIP743(-S)-EUK In-Wall Kiosk Enclosure fits 43" Displays up to 3.10" (78mm) Thick
KIP746(-S)-EUK In-Wall Kiosk Enclosure fits 46" Displays up to 3.10" (78mm) Thick

KIP747(-S)-EUK In-Wall Kiosk Enclosure fits 47" Displays up to 3.10" (78mm) Thick
KIP748(-S)-EUK In-Wall Kiosk Enclosure fits 48" Displays up to 3.10" (78mm) Thick
KIP749(-S)-EUK In-Wall Kiosk Enclosure fits 49" Displays up to 3.10" (78mm) Thick
KIP755(-S)-EUK In-Wall Kiosk Enclosure fits 55" Displays up to 3.10" (78mm) Thick

Product Specifications

	DIMENSIONS (W x H x D)	PRODUCT WEIGHT	LOAD CAPACITY	FINISH	AVAILABLE COLOURS
KIP740/742/743(-S)-EUK	28.91" x 45.41" x 5.15" (734 x 1153 x 131mm)	79lb (35kg)			KIP740/742/743/746/747/748/749/755-EUK: Gloss Black KIP740-S/742-S/743-S/746-S/747-S/748-S/749-S/755-S-EUK: Silver
KIP746/747/748(-S)-EUK	31.85" x 50.40" x 5.15" (809 x 1280 x 131mm)	87lb (39kg)	75lb (34kg)	Powder Coat	
KIP749/755(-S)-EUK	35.35" x 57.90" x 5.15" (898 x 1471 x 131mm)	97lb (44kg)			

Package Specifications

	PACKAGE SIZE (W x H x D)	PACKAGE SHIP WEIGHT	PACKAGE UPC CODE	PACKAGE CONTENTS	UNITS IN PACKAGE
KIP740/742/743(-S)-EUK	50.00" x 36.00" x 8.00" (1270 x 914 x 203mm)	90lb (41kg)	KIP740-EUK: 735029309093 KIP742-EUK: 735029309116 KIP743-EUK: 735029338307	Kiosk & Display Mounting Hardware	1
KIP746/747/748(-S)-EUK	54.00" x 39.00" x 8.00" (1371 x 990 x 203mm)	100lb (45kg)	KIP746-EUK: 735029309130 KIP747-EUK: 735029309154 KIP748-EUK: 735029309178		
KIP749/755(-S)-EUK	62.00" x 43.00" x 8.00" (1574 x 1092 x 203mm)	110lb (50kg)	KIP749-EUK: 735029338314 KIP755-EUK: 735029309192		


Accessories



KioskBuilder™:

Build your own Integrated Kiosk @ kiosks.peerless-av.com including integration services, flat panel display, media player, content management software, power protection, thermal management, display protection, vinyl graphics, etc.

All dimensions = inch (mm)

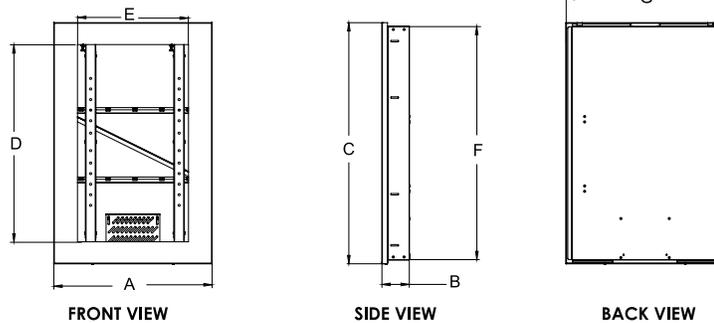

MODEL NO.	DIMENSION "A"	DIMENSION "B"	DIMENSION "C"	DIMENSION "D"	DIMENSION "E"	DIMENSION "F"	DIMENSION "G"
KIP740-EUK	29.47" (749mm)	5.05" (128mm)	44.89" (1140mm)	34.97" (888mm)	19.67" (500mm)	43.50" (1105mm)	27.25" (692mm)
KIP742-EUK	29.47" (749mm)	5.05" (128mm)	44.89" (1140mm)	36.72" (933mm)	20.65" (525mm)	43.50" (1105mm)	27.25" (692mm)
KIP743-EUK	29.47" (749mm)	5.05" (128mm)	44.89" (1140mm)	37.59" (955mm)	21.13" (537mm)	43.50" (1105mm)	27.25" (692mm)
KIP746-EUK	32.48" (825mm)	5.05" (128mm)	49.65" (1261mm)	40.20" (1021mm)	22.61" (574mm)	48.25" (1226mm)	30.25" (768mm)
KIP747-EUK	32.48" (825mm)	5.05" (128mm)	49.65" (1261mm)	41.07" (1043mm)	23.10" (587mm)	48.25" (1226mm)	30.25" (768mm)
KIP748-EUK	32.48" (825mm)	5.05" (128mm)	49.65" (1261mm)	41.94" (1065mm)	23.59" (599mm)	48.25" (1226mm)	30.25" (768mm)
KIP749-EUK	35.92" (912mm)	5.05" (128mm)	57.15" (1452mm)	42.82" (1088mm)	24.08" (611mm)	55.75" (1416mm)	33.75" (857mm)
KIP755-EUK	35.92" (912mm)	5.05" (128mm)	57.15" (1452mm)	48.05" (1220mm)	27.03" (686mm)	55.75" (1416mm)	33.75" (857mm)

Architect Specifications

The In-Wall Kiosk Enclosure shall be a Peerless-AV model KIP740(-S)-EUK, 742(-S)-EUK, 743(-S)-EUK, 746(-S)-EUK, 747(-S)-EUK, 748(-S)-EUK, 749(-S)-EUK or 755(-S)-EUK and shall be located where indicated on the plans. Assembly and installation shall be done according to instructions provided by the manufacturer.

Visit peerless-av.com to see the complete line of AV solutions from Peerless-AV, including outdoor displays, kiosks, digital audio, display mounts, projector mounts, carts/stands, and a full assortment of accessories.

Peerless-AV
 2300 White Oak Circle
 Aurora, IL 60502 USA
(800) 865-2112
(630) 375-5100
Fax: (800) 359-6500

Peerless-AV EMEA
 Unit 3 Watford Interchange
 Colonial Way, Watford
 Herts, WD24 4WP
 United Kingdom
+44 (0) 1923 200100
Fax: +44 (0) 1923 200101

Peerless-AV Latin America
 Av. de las Industrias 413
 Parque Industrial Escobedo
 General Escobedo, N.L.,
 México, 66062
+52 (81) 8384-8300
Fax: +52 (81) 8384-8360

