



Project Name: \_\_\_\_\_  
 Location: \_\_\_\_\_  
 Item #: \_\_\_\_\_ Qty: \_\_\_\_\_  
 Model: \_\_\_\_\_

## REACH-IN FREEZERS

MODEL: ☐ MXCF-19FDHC ☐ MXCF-23FDHC ☐ MXCF-49FDHC ☐ MXCF-72FDHC



MXCF-19FDHC



MXCF-23FDHC



MXCF-49FDHC



MXCF-72FDHC


Maxx Cold Reach-In Freezers store frequently accessed foodservice products within reach and at the proper storage temperature. The Reach-in Freezers are constructed of durable stainless steel, and include self-closing doors and an oversized refrigeration system to meet the needs of demanding applications.

### FEATURES AND CONSTRUCTION

- Constructed of a durable, easy to clean stainless steel exterior and painted aluminum interior
- Self-closing, locking doors with easy to grip recessed handles
- Adjustable heavy-duty wire shelves (3 per section/door)
- Open door alert beeps when door has been open for 3 minutes
- Equipped with 4" swivel casters
- Digital control system
- LED temperature display
- Automatic defrost system
- Automatic interior lighting
- Equipped with integrated condensate evaporator therefore no drain line connection is needed
- Urethane foam insulated walls and doors

### ELECTRIC

Single & Double Door: 115V / 60Hz / 1Ph  
 Triple Door: 230V / 50-60Hz / 1Ph  
 6' (2m) cord set included

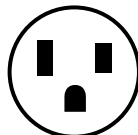

NEMA 5-15P



NEMA L14-20R

### 3RD PARTY APPROVALS



Intertek

Certified to ANSI NSF 7



Intertek

Certified to ANSI UL 471



Zero Ozone Depletion Potential



DOE 2018 Compliant

### MAXX COLD WARRANTY (USA / CANADA)

Contact Maxx Cold for warranty statement at  
 TechnicalServices@TheLegacyCompanies.com or 877.368.2797

### NOMINAL STORAGE CAPACITY


|                  |                   |
|------------------|-------------------|
| MXCF-19FDHC..... | 19 Cu Ft (538 L)  |
| MXCF-23FDHC..... | 23 Cu Ft (651 L)  |
| MXCF-49FDHC..... | 49 Cu Ft (1387 L) |
| MXCF-72FDHC..... | 72 Cu Ft (2039 L) |

### TEMPERATURE

Holding temperature ..... -10°F to 10°F (-23°C to -12°C)

- Efficient forced-air refrigeration system

# **REACH-IN FREEZERS**

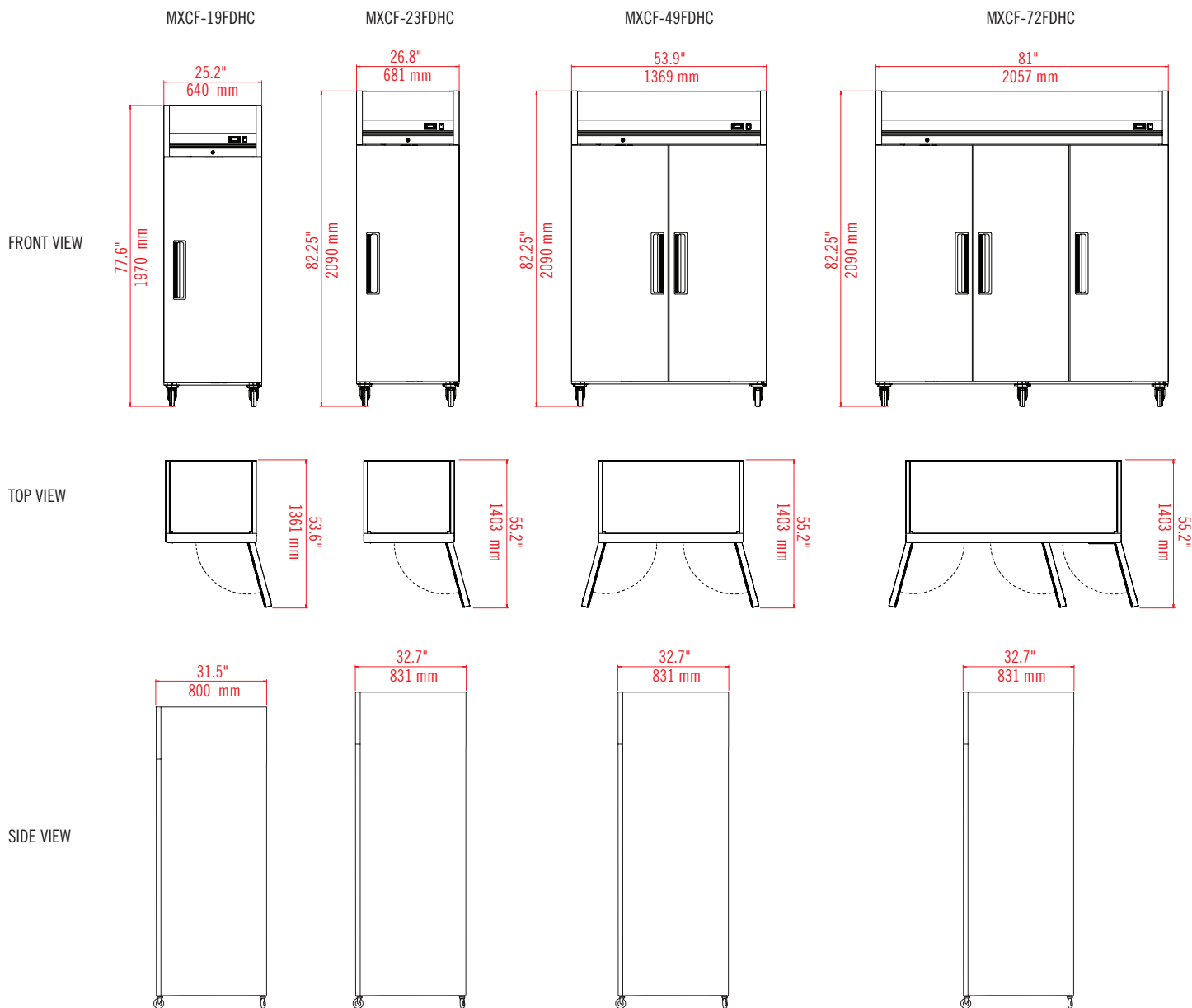

| MODEL       | EXTERNAL DIMENSIONS                              | INTERNAL DIMENSIONS                             | NOMINAL CAPACITY     | HOLDING TEMPERATURE RANGE         | AMP DRAW | SHIPPING WEIGHT     | REFRIGERANT AND CHARGE SIZE | DOORS / SHELVES | ELECTRICAL        |
|-------------|--------------------------------------------------|-------------------------------------------------|----------------------|-----------------------------------|----------|---------------------|-----------------------------|-----------------|-------------------|
| MXCF-19FDHC | 25.2" x 31.5" x 77.6"<br>(640 x 800 x 1970 mm)   | 20.25" x 28.7" x 61.8"<br>(514 x 730 x 1570 mm) | 19 Cu Ft<br>(538 L)  | -10°F to 10°F<br>(-23°C to -12°C) | 8A       | 296 lbs<br>(134 kg) | R-290A<br>3.88 oz (110 g)   | 1 / 3           | 115V / 60Hz / 1Ph |
| MXCF-23FDHC | 26.8" x 32.7" x 82.25"<br>(681 x 831 x 2090 mm)  | 21.9" x 26.5" x 52.1"<br>(556 x 673 x 1324 mm)  | 23 Cu Ft<br>(651 L)  | -10°F to 10°F<br>(-23°C to -12°C) | 8A       | 336 lbs<br>(140 kg) | R-290A<br>3.88 oz (110 g)   | 1 / 3           | 115V / 60Hz / 1Ph |
| MXCF-49FDHC | 53.9" x 32.7" x 82.25"<br>(1369 x 831 x 2090 mm) | 49.1" x 26.5" x 52.1"<br>(1246 x 673 x 1324 mm) | 49 Cu Ft<br>(1387 L) | -10°F to 10°F<br>(-23°C to -12°C) | 9A       | 502 lbs<br>(160 kg) | R-290A<br>5.29oz (150 g)    | 2 / 6           | 115V / 60Hz / 1Ph |
| MXCF-72FDHC | 81" x 32.7" x 82.25"<br>(2057 x 831 x 2090 mm)   | 76.1" x 26.5" x 52.1"<br>(1933 x 673 x 1324 mm) | 72 Cu Ft<br>(2039 L) | -10°F to 10°F<br>(-23°C to -12°C) | 9A       | 601 lbs<br>(195 kg) | R-290A<br>5.29oz (150 g)    | 3 / 9           | 230V / 60Hz / 1Ph |

## INSTALLATION

- Shorter caster options are available to lower the overall height of the unit