

REACH-IN REFRIGERATORS

MODEL: ☐ MXCR-19FDHC ☐ MXCR-23FDHC ☐ MXCR-49FDHC ☐ MXCR-72FDHC



MXCR-19FDHC



MXCR-23FDHC



MXCR-49FDHC



MXCR-72FDHC


Maxx Cold Reach-In Refrigerators store frequently accessed foodservice products within reach and at the proper storage temperature. The Reach-in Refrigerators are constructed of durable stainless steel, and include self-closing doors and an oversized refrigeration system to meet the needs of demanding applications.

FEATURES AND CONSTRUCTION

- Constructed of a durable, easy to clean stainless steel exterior and painted aluminum interior
- Self-closing, locking doors with easy to grip recessed handles
- Adjustable heavy-duty wire shelves (3 per section/door)
- Open door alert beeps when door has been open for 3 minutes
- Equipped with 4" swivel casters
- Digital control system
- LED temperature display
- Automatic defrost system
- Automatic interior lighting
- Equipped with integrated condensate evaporator therefore no drain line connection is needed
- Urethane foam insulated walls and doors

ELECTRIC

115V / 60Hz / 1Ph
 (230V / 50-60Hz / 1Ph is available as an option)
 6' (2m) NEMA 5-15P cord set included

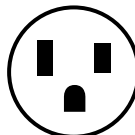

NEMA 5-15P

NOMINAL STORAGE CAPACITY

MXCR-19FDHC	19 Cu Ft (538 L)
MXCR-23FDHC	23 Cu Ft (651 L)
MXCR-49FDHC	49 Cu Ft (1387 L)
MXCR-72FDHC	72 Cu Ft (2039 L)

TEMPERATURE

Holding temperature 34°F to 41°F (1°C to 5°C)

- Efficient forced-air refrigeration system

3RD PARTY APPROVALS



Intertek

Certified to ANSI NSF 7



Intertek

Certified to ANSI UL 471



Meets Energy Star Guidelines
 MXCR-23FDHC / MXCR-49FDHC




Zero Ozone
 Depletion Potential



DOE 2018 Compliant

MAXX COLD WARRANTY (USA / CANADA)

Contact Maxx Cold for warranty statement at
 TechnicalServices@TheLegacyCompanies.com or 877.368.2797

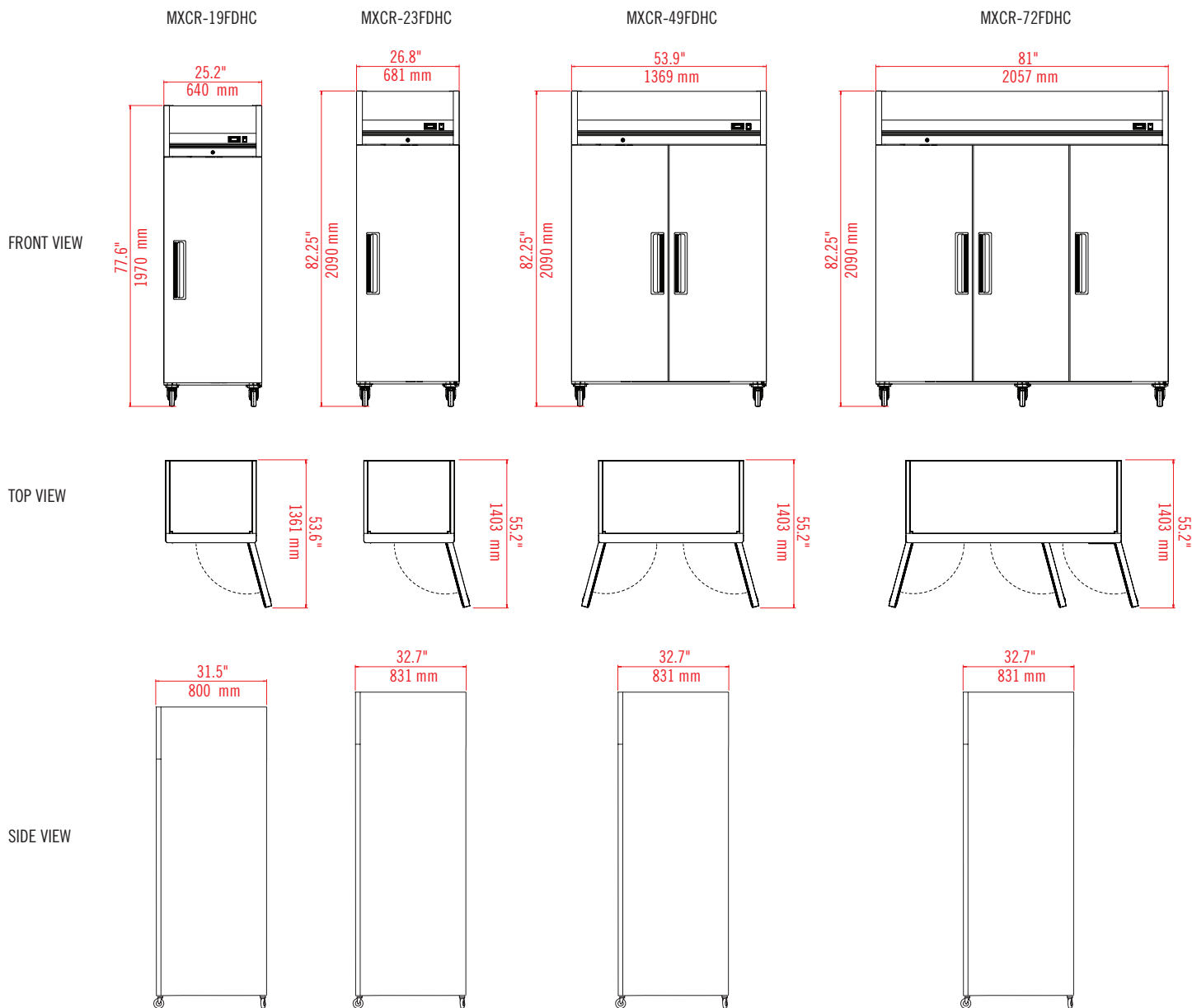

MODEL	EXTERNAL DIMENSIONS	INTERNAL DIMENSIONS	NOMINAL CAPACITY	HOLDING TEMPERATURE RANGE	AMP DRAW	SHIPPING WEIGHT	REFRIGERANT AND CHARGE SIZE	DOORS / SHELVES	ELECTRICAL
MXCR-19FDHC	25.2" x 31.5" x 77.6" (640 x 800 x 1970 mm)	20.25" x 28.7" x 61.8" (514 x 730 x 1570 mm)	19 Cu Ft (538 L)	34°F to 41°F (1°C to 5°C)	3A	291 lbs (132 kg)	R-290A 3.0 oz (85 g)	1 / 3	115V / 60Hz / 1Ph
MXCR-23FDHC	26.8" x 32.7" x 82.25" (681 x 831 x 2090 mm)	21.9" x 26.5" x 52.1" (556 x 673 x 1324 mm)	23 Cu Ft (651 L)	34°F to 41°F (1°C to 5°C)	3A	311 lbs (143 kg)	R-290A 3.0 oz (85 g)	1 / 3	115V / 60Hz / 1Ph
MXCR-49FDHC	53.9" x 32.7" x 82.25" (1369 x 831 x 2090 mm)	49.1" x 26.5" x 52.1" (1246 x 673 x 1324 mm)	49 Cu Ft (1387 L)	34°F to 41°F (1°C to 5°C)	4.5A	536 lbs (244 kg)	R-290A 3.7 oz (105 g)	2 / 6	115V / 60Hz / 1Ph
MXCR-72FDHC	81" x 32.7" x 82.25" (2057 x 831 x 2090 mm)	76.1" x 26.5" x 52.1" (1933 x 673 x 1324 mm)	72 Cu Ft (2039 L)	34°F to 41°F (1°C to 5°C)	7A	639 lbs (291 kg)	R-290A 5.29 oz (150 g)	3 / 9	220V / 60Hz / 1Ph

INSTALLATION

- Shorter caster options are available to lower the overall height of the unit