

### Features

- 8" (203 mm) widespread faucet holes.
- Oval basin.
- Overflow drain.
- Combination consists of the K-2028-8 sink and the K-2057 shroud.

### Material

- Vitreous china.

### Installation

- Wall-mount.

### Recommended Products/Accessories

K-7605-P Angle Supply with Stop (pair)

K-8998 P-Trap

K-23726 Drain treatment

K-23725 Cast iron cleaner

### Included Components

Product consists of:

K-2028-8 Wall-mount Bathroom Sink

K-2057 Bathroom Sink Shroud

Additional Components:

Hanger(s)

Rubber pads

shroud accessory pack



ADA

OBC

### Codes/Standards

ASME A112.19.2/CSA B45.1

ADA

ICC/ANSI A117.1

OBC

### KOHLER® One-Year Limited Warranty

See website for detailed warranty information.

### Available Colors/Finishes

*Color tiles intended for reference only.*

Color	Code	Description
-------	------	-------------




0

White



96

Biscuit

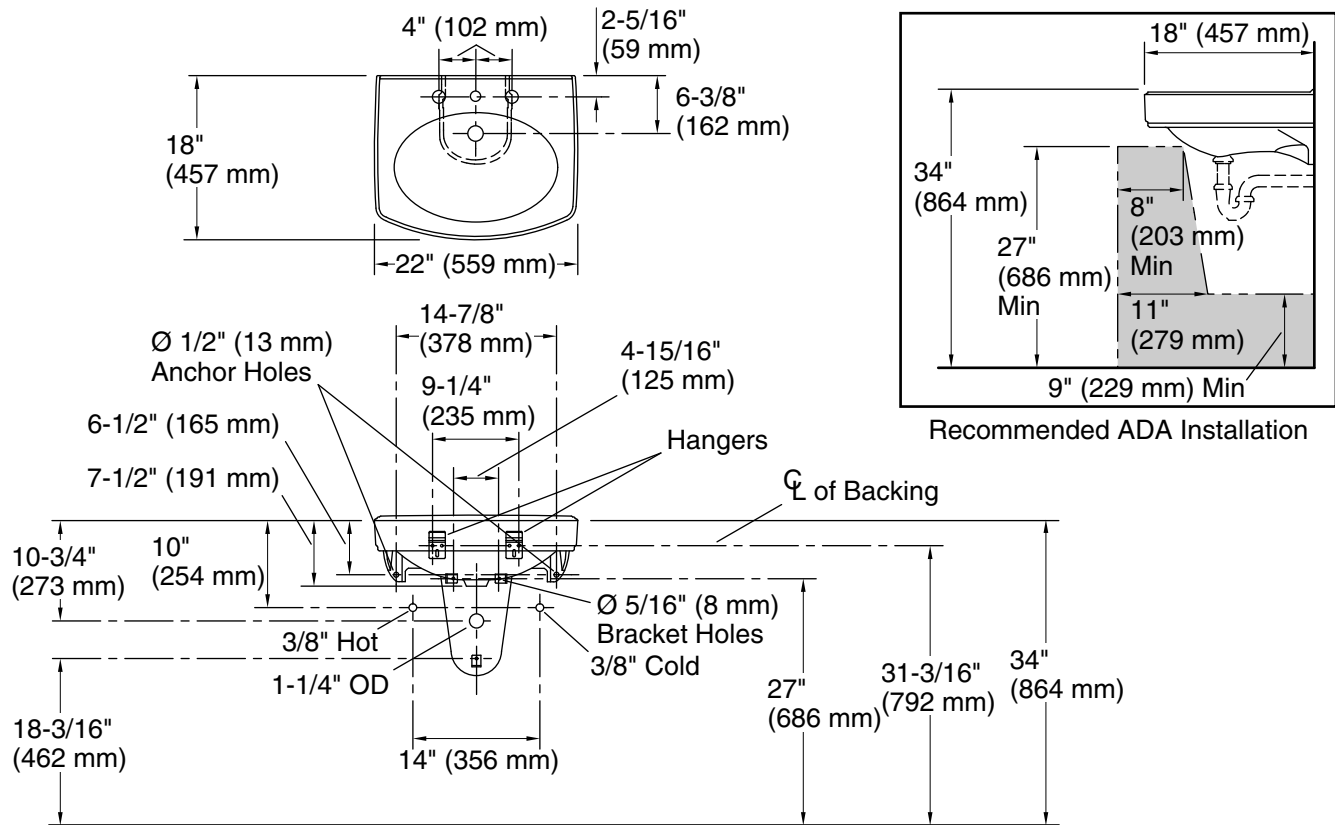

## Technical Information

All product dimensions are nominal.

Bowl configuration:	Single
Installation:	Wall-mount
Bowl area (Only):	Length: 18" (457 mm) Width: 12" (305 mm) Water depth: 4" (102 mm)
Number of deck holes:	3
Faucet hole spacing:	8" (203 mm)
Faucet hole(s):	1-3/8" (35 mm)
Drain hole:	1-3/4" (44 mm)

## Notes

Install this product according to the installation instructions.

ADA, OBC compliant when installed to the specific requirements of these regulations.