

CODE NUMBER

2112229

DESCRIPTION

Bed Pan Lugs, Vitreous China Floor-Mounted Rear Outlet Water Closet.

DETAILS

- Flush Volume: 1.28-1.6 gpf (4.8-6.0 Lpf)
- Flush volume determined by the flushometer used with the fixture
- Rim Height: 16 ½" (419mm)
- Nominal Dimensions: 26 ¾" x 14" x 16 ½" (679 x 356 x 419mm)
- Bed Pan Lugs: Yes (BPL)

FEATURES

- White Vitreous China
- Elongated bowl
- Floor mounted, rear outlet
- Water spot area: 10¾" x 8" (26 cm x 24 cm)
- 1½" I.P.S. top spud inlet
- 2½" fully glazed trapway
- Closet bolts and caps included
- Toilet seat not included
- Static load rating of 1000 lbs. (See Notes)

RECOMMENDED SEATS

- Bemis - 1955CT/1955SSCT & 2155CT/2155SSCT
- Church - 295CT/295SSCT & 2155CT/2155SSCT

PLUMBING SYSTEM REQUIREMENTS


- Minimum Flowing Pressure: 25 PSI (172 kPa)
- Maximum Static Pressure: 80 PSI (552 kPa)

DOWNLOADS

- [HET ST-2229 Series Installation Instructions](#)
- [SS/ST/SU/WETS/WEUS Fixtures Repair and Maintenance Guide](#)
- [Additional Downloads](#)



COMPLIANCES & CERTIFICATIONS

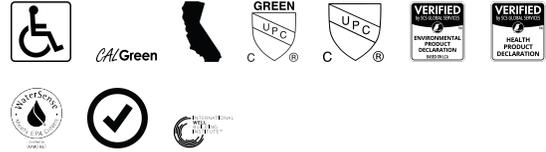

(ADA Compliant, CalGreen Compliant, CEC Compliant, cUPC Green Certified, cUPC Certified, EPD, HPD, WaterSense Listed, Satisfies LEED Credits, WELL Building Standard)

NOTES

All information contained within this document subject to change without notice.

All vitreous china dimensions shown in these drawings are nominal and not to scale. Dimensions can vary within the tolerances established in the governing ASME A112.19.2/CSA B45.1 standard. It is important to consider this when planning rough-in and plumbing layouts.

Static load tested according to the procedure outlined in Section 6.7 of ASME A112.19.2. Not recommended for bariatric use.


[Find a compatible flushometer](#) for this water closet.

WaterSense compliant when used with a WaterSense compliant flushometer

WARRANTY

[View Warranty Information](#)

ROUGH-IN

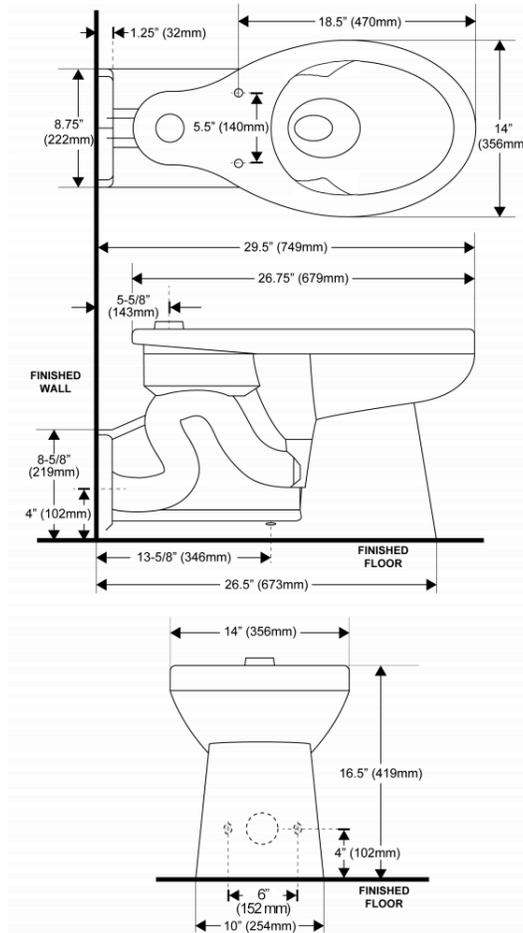

Sloan 10500 Seymour Ave, Franklin Park, IL 60131
 Phone: 800.982.5839 • Fax: 800.447.8329 • sloan.com