

MOEN®

Specifications

DESCRIPTION

- Various finishes identified by suffix
- Magnetix™ technology features an innovative magnetic docking system
- Includes rainshower, handshower, hose and magnetic docking system
- 60" double interlock spiral hose (metal), for Chrome and Spot Resist Brushed Nickel finishes
- 19" slide bar push button height selection
- 1/2" IPS connection


OPERATION

- Rainshower is single function, Handshower is six functions
- Rotate outer ring to select function
- 3-way diverter provides ability to flow each shower head separately or combined for more coverage
- Pause/trickle button allows to momentarily pause the handshower flow at a push of a button
- Handshower cradle rotates to adjust angle of handshower

FLOW


- Showerhead is limited to 2.5 gpm (9.5 L/min) MAX at 80 psi
- Handshower is limited to 2.5 gpm (9.5 L/min) MAX at 80 psi

STANDARDS

- Designed and manufactured to comply with the applicable requirements of ASME A112.18.1/CSA B-125.1, and all applicable specifications referenced therein
- Products marked with 1.75 gpm are compliant with California water efficiency regulations
- **ADA**  compliant

WARRANTY


- Lifetime limited warranty against leaks, drips and finish defects to the original homeowner
 - 10 year limited warranty when used in a multifamily installation
 - 5 year limited warranty when used in a commercial installation
- Visit www.moen.com/support for complete details and limitations

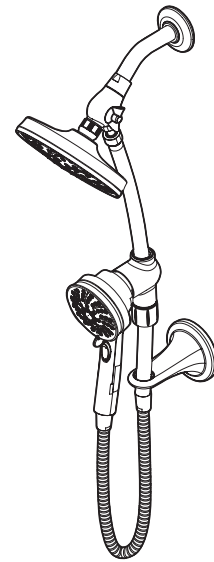

ATTRACT™

Magnetix™ Rainshower with Handheld Combo Slide Bar

Model: 28586 SERIES

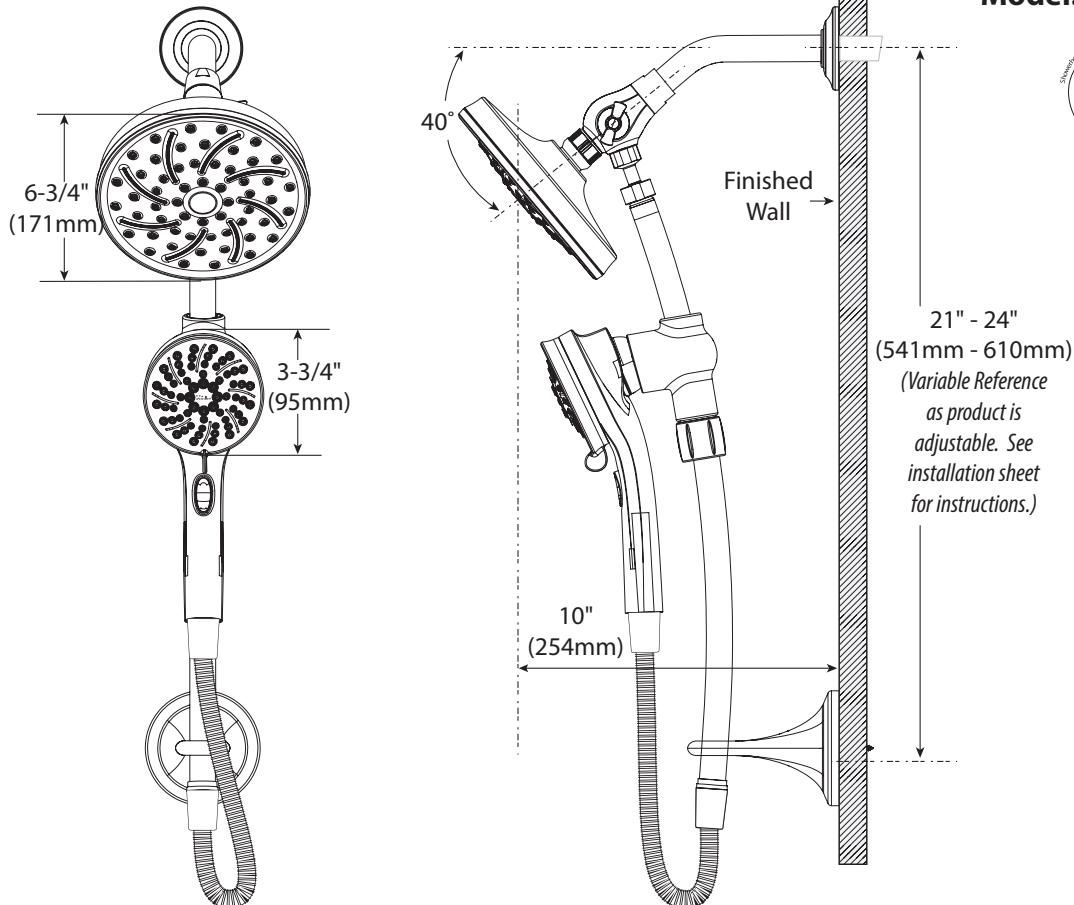

CRITICAL DIMENSIONS

(DO NOT SCALE)