



# Deluxe

Sliding bath door, 56-1/4" H x 59-3/8" W  
5905-3G05

## Features

- 1/8" (3 mm) thick tempered and fully framed Clear glass ensures enhanced safety and durability
- Bypass system allows for easy access and suits your bathroom layout whether your showerhead is on the right or left
- Reversible top track and towel bar allow a choice between rounded or accented design
- Continuous bottom track guide system for smooth, quiet, and stable operation
- Made in the U.S.A

## Material

- Anodized aluminum prevents rust and corrosion

## Installation

- Fits opening widths 54-3/8" - 59-3/8" (1381 - 1508 mm)
- Requires 2" (51 mm) minimum threshold depth
- Out-of-plumb adjustability simplifies installation
- For residential use only
- Not for use in hospitality

## Included Components

Additional Components:  
Hardware Kit



## Codes/Standards

ANSI Z97.1  
CPSC 16CFR 1201


## STERLING® Bath and Shower Doors Three-Year Limited Warranty

See website for detailed warranty information.

## Available Colors/Finishes

*Color tiles intended for reference only.*

Color	Code	Description
-------	------	-------------

	S	Silver
---	---	--------

## Available Glass Options

Code	Description
------	-------------


G05	Clear
-----	-------

1-800-STERLING (1-800-783-7546)

Kohler Co. reserves the right to make revisions without notice to product specifications.

For the most current Specification Sheet, go to [www.sterlingplumbing.com](http://www.sterlingplumbing.com).

3-26-2023 00:11 - US

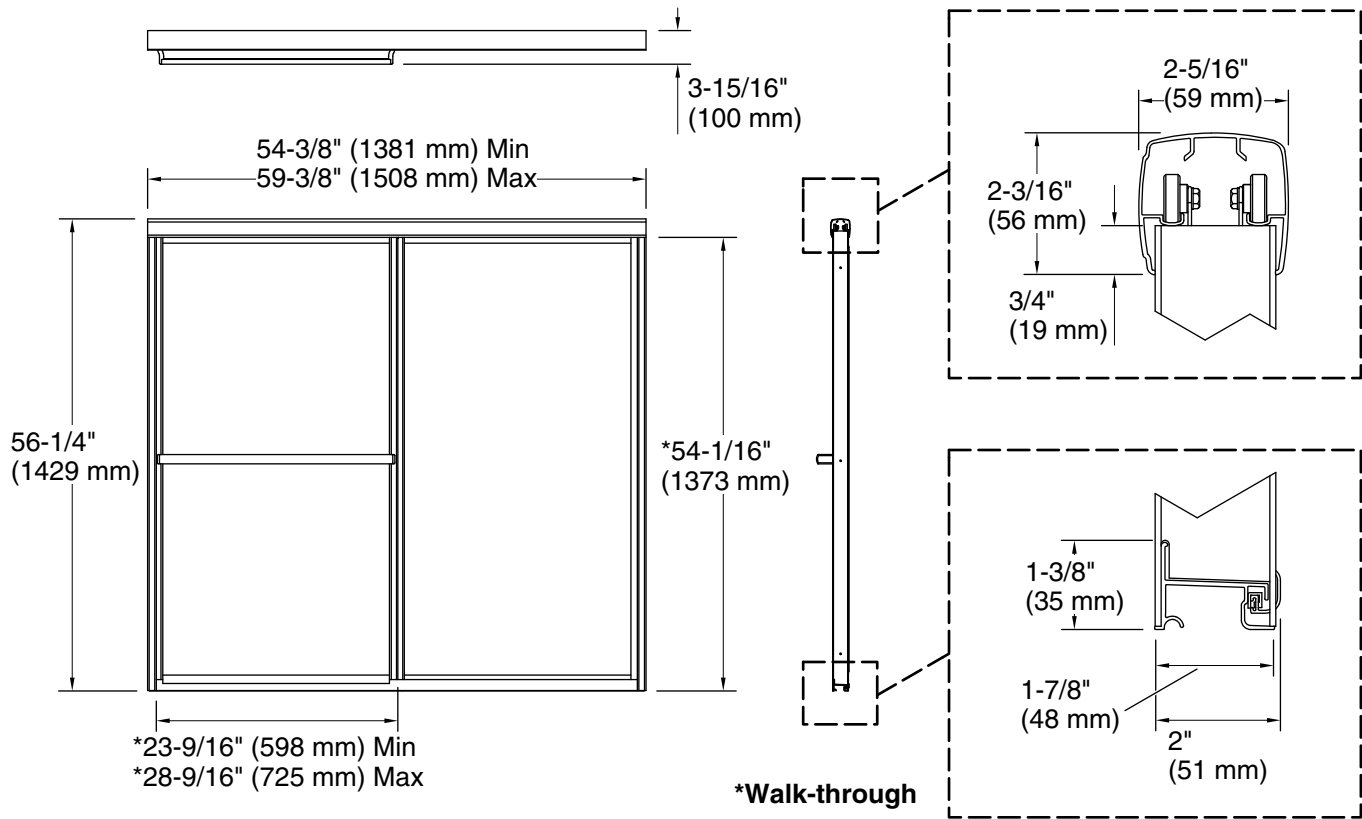

**Technical Information**

All product dimensions are nominal.  
 Installation type: For bath installation  
 Base-To-Wall 1/2" (13 mm)  
 Radius – Max:  
 Glass thickness: 1/8" (3 mm)

**Notes**

Install this product according to the installation instructions.  
 The vertical opening should be a minimum of 57-11/16" (1465 mm) to allow for installation clearance.