

AquaStat

Specifications

Description: Thermostatic Switch

Type: Bi-metallic Disc, Snap acting

Enclosure: Environmentally Sealed



Mounting:

Clip on mount for 1/2" I.D. copper tube (5/8" O.D.)

Clip on mount for 3/4" I.D. copper tube (7/8" O.D.)

Contact Rating:

10 amp @ 120 VAC 60 Hz resistive

5 amp @ 240 VAC 60 Hz resistive

Temperature Rating:

Low Temp Model

105+5°F (40+2°C) Pump switches off

85+6°F (29+3°C) Pump switches on

High Temp Model

115+5°F (46+2°C) Pump switches off

105+5°F (40+2°C) Pump switches on


Leads:

2 leads, AWG 18, 14"

12", black insulation, silicon or epoxy overmold

1/2" STRIP LENGTH

Application: Clip-on thermostatic control for the UP Circulators

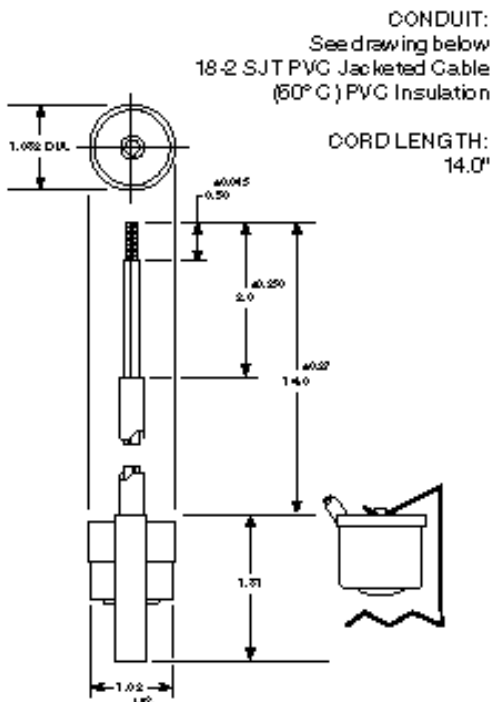

NOTE: All dimensions are in inches.

* Temperatures indicated are at pipe surface.