



River Falls™
Undermount Utility Sink
K-6657-4U

Features

- 27" (686 mm) minimum base cabinet width.
- Single bowl.
- 14-1/4" depth provides generous workspace.
- Four oversized faucet holes.
- Oversized holes allow for easy installation of faucets and accessories.
- Strainer sold separately.

Material

- KOHLER® enameled cast iron.

Installation

- Undermount installation kit not included.
- Undermount.

Recommended Products/Accessories

- K-8801 Sink drain and strainer with tailpiece
- K-8799 Sink drain and strainer basket
- K-11352 Disposal Flange with Stopper
- K-9000 P-Trap
- 1411886 Undermount sink kit 23"
- K-23726 Drain treatment
- K-23725 Cast iron cleaner

Included Components

Additional Components:

- Cut-out template
- Soaking pan
- Wire rack



Codes/Standards

ASME A112.19.1/CSA B45.2


**KOHLER® Enameled Cast Iron
Kitchen Sink Lifetime Limited
Warranty**

See website for detailed warranty information.

Available Colors/Finishes

Color tiles intended for reference only.

Color	Code	Description
	0	White
	FF	Sea Salt™
	96	Biscuit
	NY	Dune
	95	Ice™ Grey
	K4	Cashmere
	FT	Basalt
	58	Thunder™ Grey
	FP	Caviar
	7	Black Black™

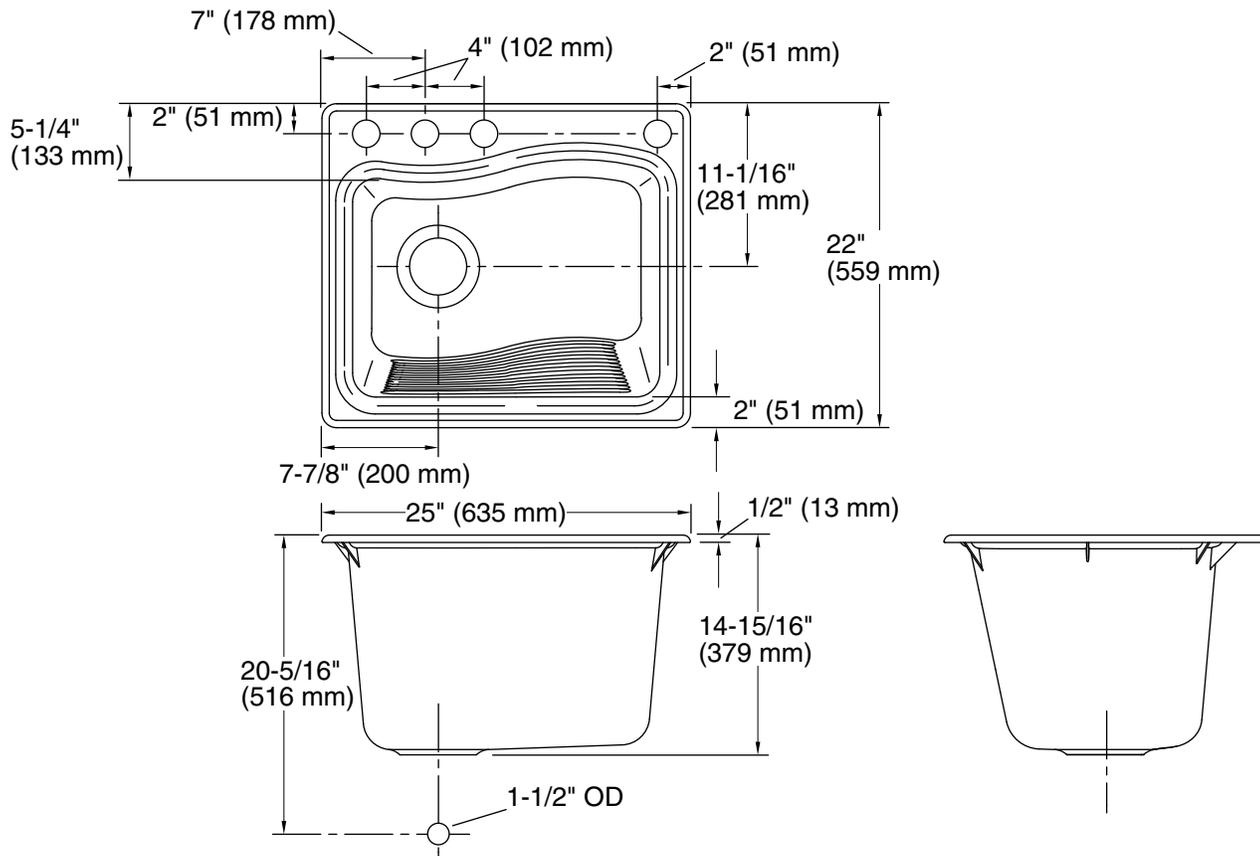

Technical Information

All product dimensions are nominal.

Bowl configuration: Single

Installation: Undermount

Min. base cabinet width: 27" (686 mm)

Bowl area: Length: 21-1/2" (546 mm)
Width: 14-3/4" (375 mm)
Bowl depth: 14-1/4" (362 mm)

Number of deck holes: 4

Faucet hole spacing: 4" (102 mm)

Faucet hole(s): 2-3/8" (60 mm)

Drain hole: 3-5/8" (92 mm)

Template: 1079984-7, required, included

Notes

Install this product according to the installation instructions.