
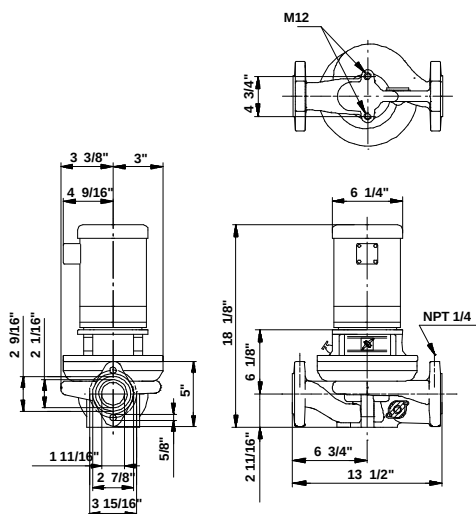



Position	Count	Description	Unit price
	-1	TP 40-40/4 B U-G-Z-BUBE  Product photo could vary from the actual product Product No.: 96411792 Single-stage centrifugal in-line single-head pump. The in-line design with opposite suction and discharge ports enables mounting in pipework or on a concrete foundation. The shaft seal is a corrosion-resistant maintenance-free mechanical seal. The motor is a 1-phase AC motor. Liquid: Liquid temperature range: 5 .. 284 °F Liquid temp: 68 °F Technical: Speed for pump data: 1770 rpm Actual calculated flow: 44 US gpm Resulting head of the pump: 9.96 ft Shaft seal: BUBE Maximum operating pressure: 145 psi Approvals on motor nameplate: UL Recognized Component, CSA Materials: Pump housing: Bronze DIN W.-Nr. 2.1093 Impeller: Stainless steel DIN W.-Nr. 1.4301 AISI 304 Installation: Maximum ambient temperature: 104 °F Maximum operating pressure: 145 psi Flange standard: USA Pipe connection: 1 1/2" Electrical data: Motor type: Baldor, TEFC	On request

Position	Count	Description	Unit price
		Number of poles: 4 Rated power - P2: 0.335 HP Main frequency: 60 Hz Rated voltage: 1 x 115/208-230 V Service factor: 1,35 Rated current: 6/3,2-3 A Starting current: 26/14,4-13 A Cos phi - power factor: 60 Rated speed: 1725 rpm Motor efficiency at full load: 60 % Insulation class (IEC 85): B Others: Net weight: 60.2 lb Gross weight: 67.5 lb Shipping volume: 1.98 ft ³	

Description	Value
Product name:	TP 40-40/4 B U-G-Z-BUBE U-G-Z BUBE
Product Number:	96411792
EAN number:	5700390523930
Technical:	
Speed for pump data	1770 rpm
Actual calculated flow:	44 US gpm
Resulting head of the pump:	9.96 ft
Head max:	13.1 ft
Shaft seal:	BUBE
Maximum operating pressure	145 psi
Approvals on motor nameplate:	UL Recognized Component, CSA
Pump Number:	96405254
Pump version:	U
Materials:	
Pump housing:	Bronze
	DIN W.-Nr. 2.1093
Impeller:	Stainless steel
	DIN W.-Nr. 1.4301
	AISI 304
Material code:	Z
Installation:	
Maximum ambient temperature:	104 °F
Maximum operating pressure	145 psi
Flange standard:	USA
Connect code:	G
Pipe connection:	1 1/2"
Liquid:	
Liquid temperature range	5 .. 284 °F
Liquid temp:	68 °F
Electrical data:	
Motor type:	Baldor, TEFC
Number of poles:	4
Rated power - P2:	0.335 HP
KVA code:	L
Main frequency:	60 Hz
Rated voltage:	1 x 115/208-230 V
Service factor:	1,35
Rated current:	6/3,2-3 A
Starting current	26/14,4-13 A
Load current:	6,8/3,6-3,4 A
Cos phi - power factor:	60
Rated speed:	1725 rpm
Motor efficiency at full load:	60 %
Insulation class (IEC 85):	B
Motor protection:	CONTACT
Thermal protec:	internal
Motor Number:	84654601
Others:	
Net weight:	60.2 lb
Gross weight:	67.5 lb
Shipping volume:	1.98 ft³
Country code:	Namreg

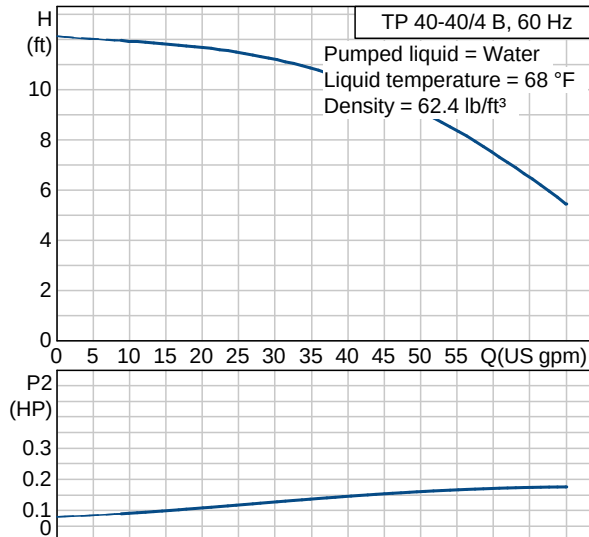

96411792 TP 40-40/4 B 60 Hz

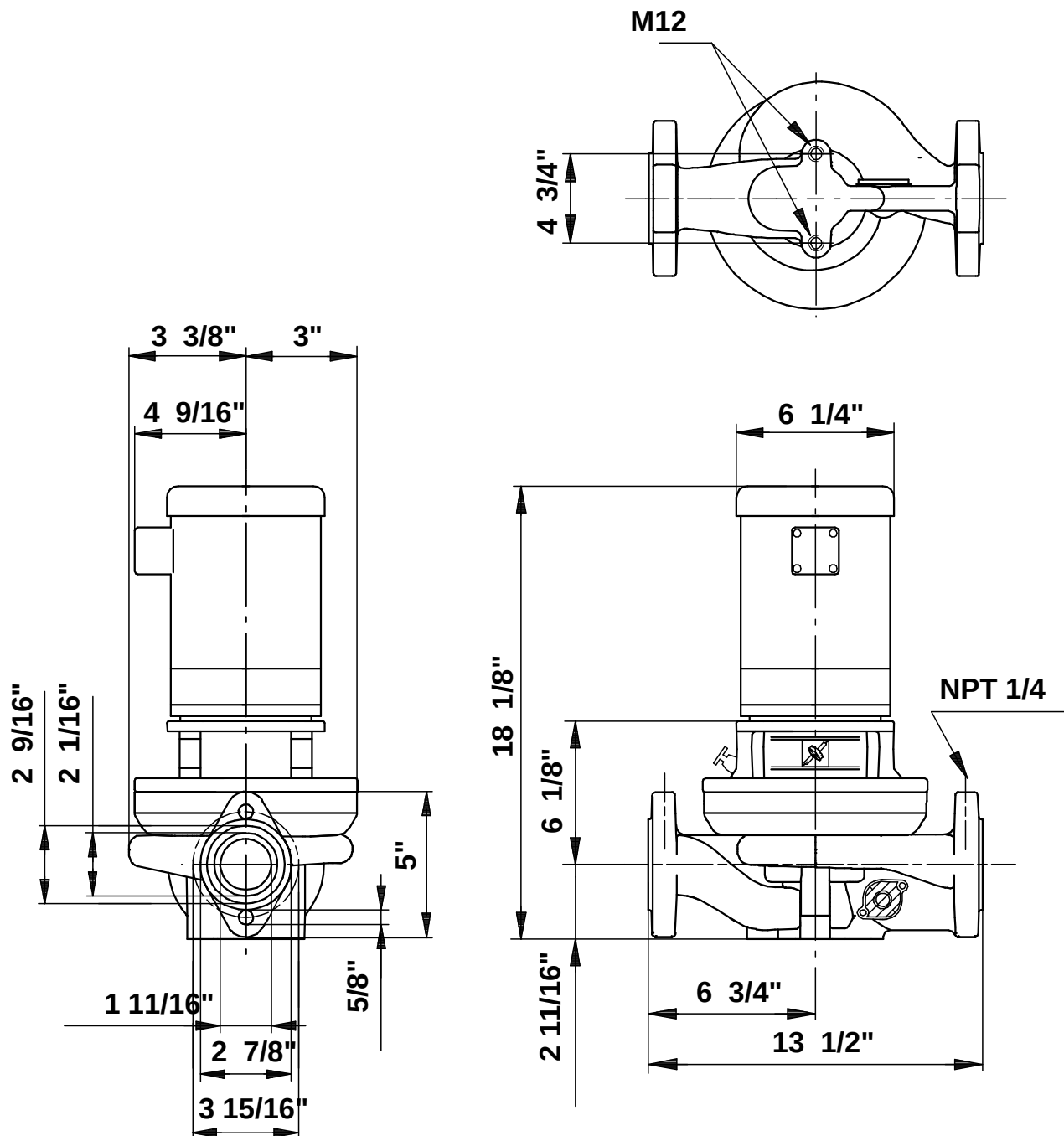

Note! All units are in [mm] unless others are stated.
 Disclaimer: This simplified dimensional drawing does not show all details.