

Features

- Well-designed seamless integration of Amazon Alexa minimizes clutter and delivers optimal interaction.
- Amazon Alexa-enabled so you can ask to play music, hear the news, check weather, control smart home devices, and more.
- Integrated stereo sound system fills the room with complete sound quality.
- Built-in microphone for voice control interaction.
- Voice control of optimally bright task lighting on/off, brightness, and sound volume.
- 2200 lumen brightness ensures consistent lighting with no hot spots or dark spots.
- Approx. 3000 Kelvin light appearance delivers a neutral light ideal for overall bathroom aesthetics as well as tasks.
- Greater than 90 CRI* lets you see yourself in the truest light for makeup application, grooming, and skin care.
- High-efficiency LED achieves over 65 lumens/watt*.
- Integrated LED bulbs have an estimated life expectancy of 36,000 hours.
- Down-firing way-finding light brightens via proximity sensor.
- Compatible with wall-mount LED dimmers (not included), which allow you to control lighting from multiple locations in the space.
- Pivoting side panels allow you to direct light for specific tasks.
- Syncs with devices enabled with BLUETOOTH® wireless technology including smartphones, MP3 players, tablets, and laptops located up to 33 feet away.*

Material

- Anodized aluminum construction with a durable rust-proof and chip-resistant finish.

Installation


- Includes mounting hardware for surface installation.

Recommended Products/Accessories

K-23723 Faucet cleaner

Included Components

Additional Components:
Mounting hardware

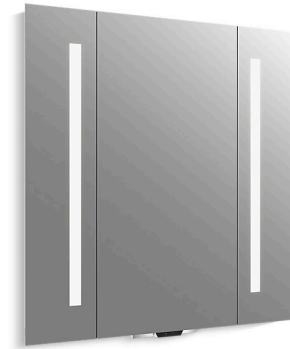




Codes/Standards

UL 962
C22.2 No. 0
CA Title 24 JA8

KOHLER® One-Year Limited Warranty

See website for detailed warranty information.

 The BLUETOOTH® word mark and logos are registered trademarks owned by Bluetooth SIG, Inc. and any use of such marks by Kohler Co. is under license. Other trademarks and trade names are those of their respective owners.

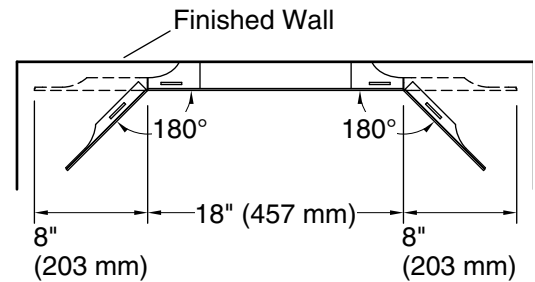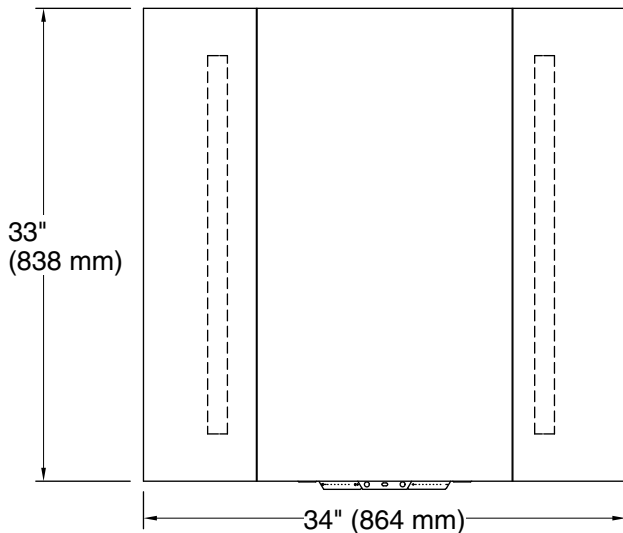

Required Electrical Service

One dedicated circuit required, protected with Class A Ground-Fault Circuit-Interrupter (GFCI). Outside North America, this device may be known as a Residual Current Device (RCD).

Lights: 120 V, 15 A, 60 Hz

Technical Information

All product dimensions are nominal.

Mirror type: Wall-mount pivot

Bluetooth® range: 33 ft (0.8 m)

Bluetooth® version: 4.0

Lighting included: Yes

Electrical component rating: Lights: 120 V, 0.3 A, 60 Hz, 36 W

Notes

Install this product according to the installation instructions.

Select the type of fastener based on the wall material. A minimum 20 lb (9.07 kg) load bearing fastener is recommended.

Install the fastener to a stud to avoid possible property and product damage.