

Features

- Apron designed to fit in standard 30" (762 mm) apron-front cabinetry
- Single bowl
- 9-1/2" (241 mm) depth provides generous workspace
- Offset drain increases workspace in the sink and storage space underneath
- Self-Trimming® apron overlaps cabinet face for easy installation and beautiful results
- Matte finish offers rich, dimensional color

Material

- KOHLER Neoroc composite material is thermal shock-resistant and heat-resistant to 750°F
- Color-dense Neoroc material helps to minimize the appearance of scratches and stains

Installation

- Undermount

Recommended Products/Accessories

- K-8801 Sink drain and strainer with tailpiece
- K-8799 Sink drain and strainer basket


Optional Products/Accessories

- K-11352 Disposal Flange with Stopper
- K-9000 P-Trap

Included Components

Additional Components:

- 26026
- 30181

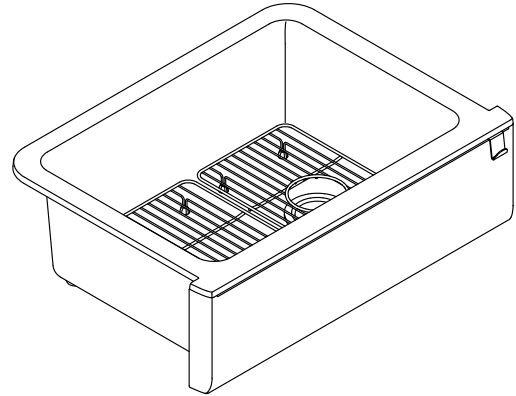


Codes/Standards

CSA B45.5/IAPMO Z124

KOHLER® Neoroc® Sinks Lifetime Limited Warranty

See website for detailed warranty information.

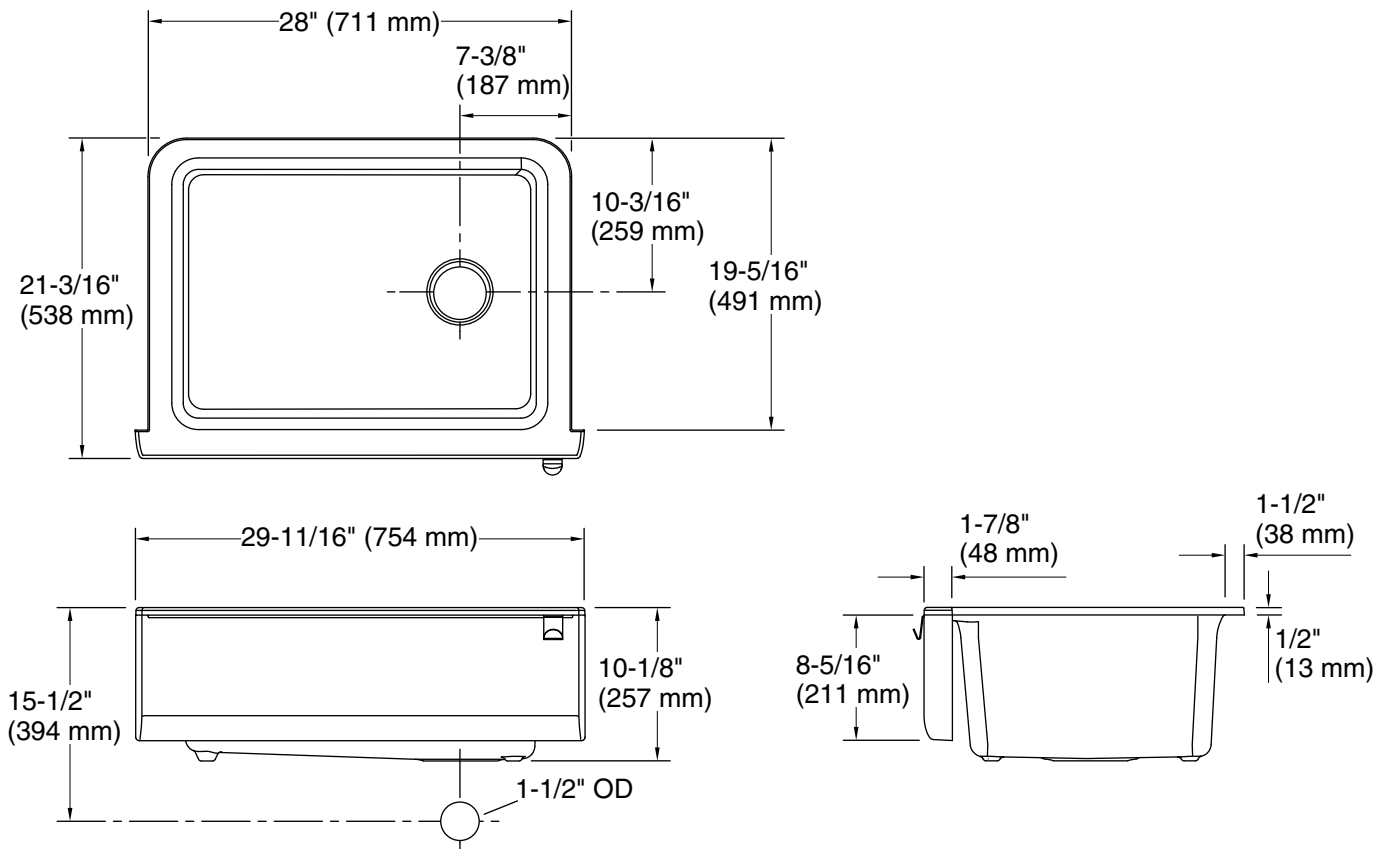

Technical Information

All product dimensions are nominal.

Installation:	Undermount
Min. base cabinet width:	30" (762 mm)
Bowl area (Only):	Length: 24-1/2" (622 mm) Width: 17-5/8" (447 mm) Bowl depth: 9-1/2" (241 mm) Water depth: 9-1/2" (241 mm)
Template:	Undermount, 1477787-7, required, included

Notes

Install this product according to the installation instructions.