

#### Features

- 36" (914 mm) minimum base cabinet width
- Single bowl
- 5" (127 mm) depth provides easy accessibility
- Rear offset drain increases workspace in the sink and storage space underneath
- No faucet holes; requires wall- or deck-mount faucet
- Matte finish offers rich, dimensional color
- Includes K-6639 bottom sink rack
- Sink drain and strainer sold separately

#### Material

- KOHLER Neoroc composite material is thermal shock-resistant and heat-resistant to 750°F
- Color-dense Neoroc material helps to minimize the appearance of scratches and stains

#### Installation

- Undermount

#### Included Components

Additional Components:  
6639



ADA

#### Codes/Standards






 
CSA B45.5/IAPMO Z124  
ADA  
ICC/ANSI A117.1


#### KOHLER® Neoroc™ Sinks Lifetime Limited Warranty

See website for detailed warranty information.

#### Available Colors/Finishes

*Color tiles intended for reference only.*

Color	Code	Description
	CM6	Matte White
	CM7	Matte Graphite
	CM2	Matte Brown
	CM3	Matte Taupe
	CM4	Matte Grey
	CM1	Matte Black

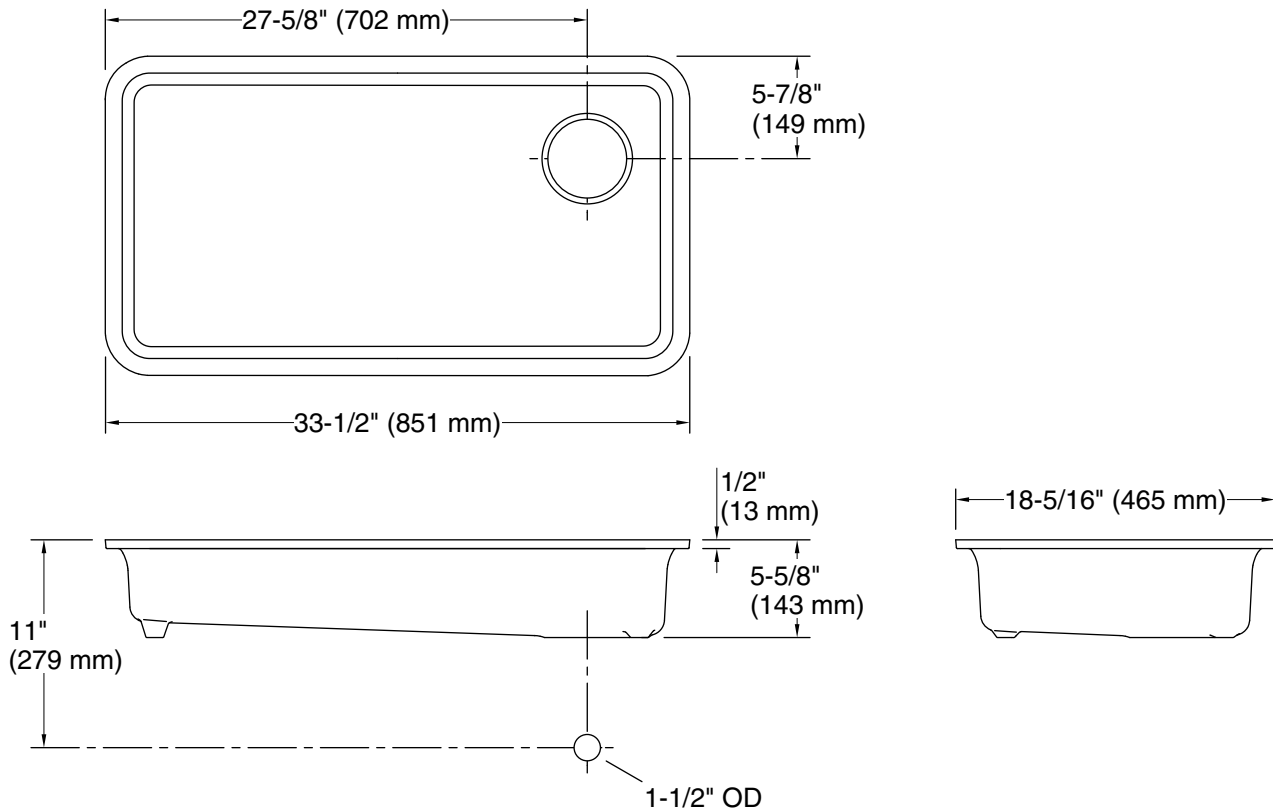

## Technical Information

All product dimensions are nominal.

Bowl configuration:	Single
Installation:	Undermount
Center(s):	4
Min. base cabinet width:	36" (914 mm)
Bowl area (Only):	Length: 30-1/2" (775 mm) Width: 15-5/16" (389 mm) Bowl depth: 5" (127 mm) Water depth: 5" (127 mm)
Number of deck holes:	1
Faucet hole spacing:	4" (102 mm)
Drain hole:	3-7/8" (98 mm)
Template:	Undermount, 1256394-7, required, included

## Notes

Install this product according to the installation instructions.

**NOTICE:** Countertop manufacturer or cutter must use the cut-out template provided with the product, or a current one provided by Kohler Co. (call 1-800-4-KOHLER). Kohler Co. is not responsible for cutout errors when the incorrect cut-out template is used.

ADA compliant when installed to the specific requirements of these regulations.