



Dickinson™
33" undermount single-bowl farmhouse kitchen sink
K-6546

Features

- Fits minimum 36" (914 mm) apron sink base cabinet
- Single bowl
- 8" (203 mm) depth
- Integral apron
- Sink drain with strainer sold separately
- No faucet holes; requires wall- or counter-mount faucet

Material

- KOHLER® enameled cast iron
- Acid-resistant enamel finish

Installation

- Undermount



Codes/Standards




ASME A112.19.1/CSA B45.2


**KOHLER® Enameled Cast Iron
Kitchen and Bathroom Sink Lifetime
Limited Warranty**

See website for detailed warranty information.

Available Colors/Finishes

Color tiles intended for reference only.

Color	Code	Description
	0	White
	96	Biscuit
	7	Black Black™

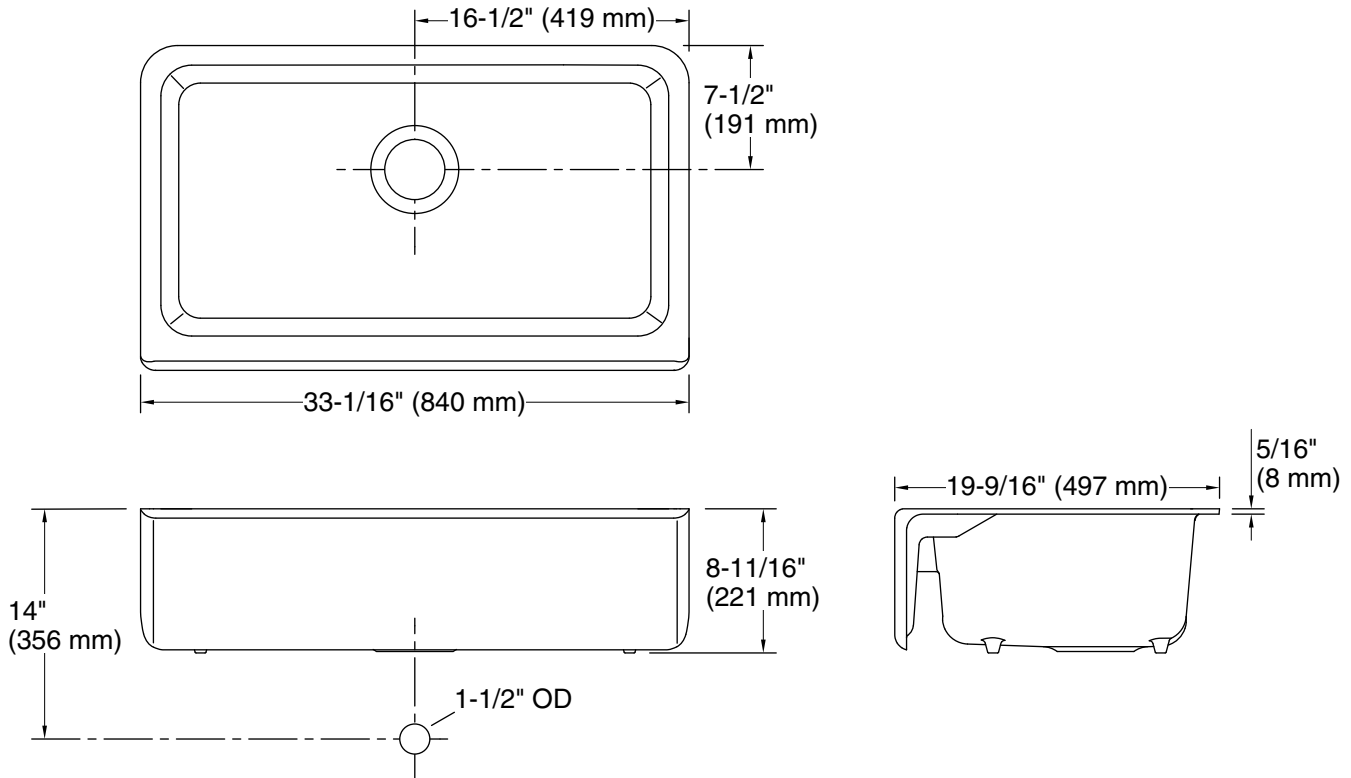

Technical Information

All product dimensions are nominal.

Installation:	Undermount
Min. base cabinet width:	36" (914 mm)
Bowl area (Only):	Length: 29-1/2" (749 mm) Width: 15-3/8" (390 mm) Bowl depth: 8-5/8" (220 mm) Water depth: 8" (203 mm)
With overflow:	No
Drain hole:	3-5/8" (92 mm)
Template:	Apron-front, 1463896-7, required, included Cabinet, 1465115-7, required, included

Notes

Install this product according to the installation instructions.