

### Features

- Spray performance delivers a drenching rain experience
- Angled nozzles provide a full-coverage spray
- Adjustable swivel ball joint allows for precise spray adjustment
- MasterClean™ sprayface features an easy-to-clean surface that withstands mineral buildup and maximizes spray performance
- 2.5 gpm (9.5 lpm) maximum flow rate at 45 psi (3.1 bar)
- Recommended for use with HydroRail® shower columns K-45210, K-45212, K-45211, and K-45209 (sold separately)
- Coordinates with other products in the Awaken collection

### Material

- Durable material construction
- KOHLER® finishes resist corrosion and tarnishing

### Installation

- Wall- or ceiling-mount
- 1/2 -14 NPT connection
- Shower arm and flange sold separately

### Recommended Products/Accessories

K-23723 Faucet cleaner



### Codes/Standards



 


ASME A112.18.1/CSA B125.1  
DOE - Energy Policy Act 1992


### KOHLER® Faucet Lifetime Limited Warranty

See website for detailed warranty information.

### Available Colors/Finishes

*Color tiles intended for reference only.*

Color	Code	Description
	CP	Polished Chrome
	BN	Vibrant® Brushed Nickel
	2BZ	Oil-Rubbed Bronze
	BL	Matte Black
	2MB	Vibrant® Brushed Moderne Brass

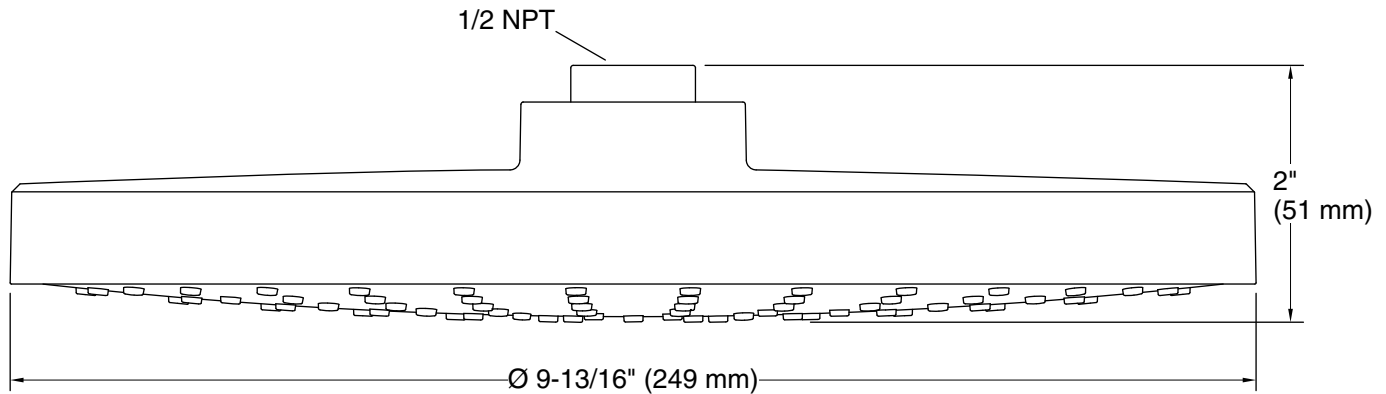

### Technical Information

All product dimensions are nominal.

#### Showerhead/Body Spray:

Rated maximum flow: 2.5 gal/min (9.5 l/min)

Pressure: 45 psi (3.1 bar)

### Notes

Install this product according to the installation instructions.