

Features

- For sink installations with 3-1/2" (89 mm) or 4" (102 mm) outlet
- Removable basket strainer with open/close stopper that seals tightly
- Less tailpiece
- 4-1/2" (114 mm) x 2-7/8" (73 mm)

Material

- Solid-brass construction for durability and reliability



Codes/Standards







 
 


ASME A112.18.2/CSA B125.2

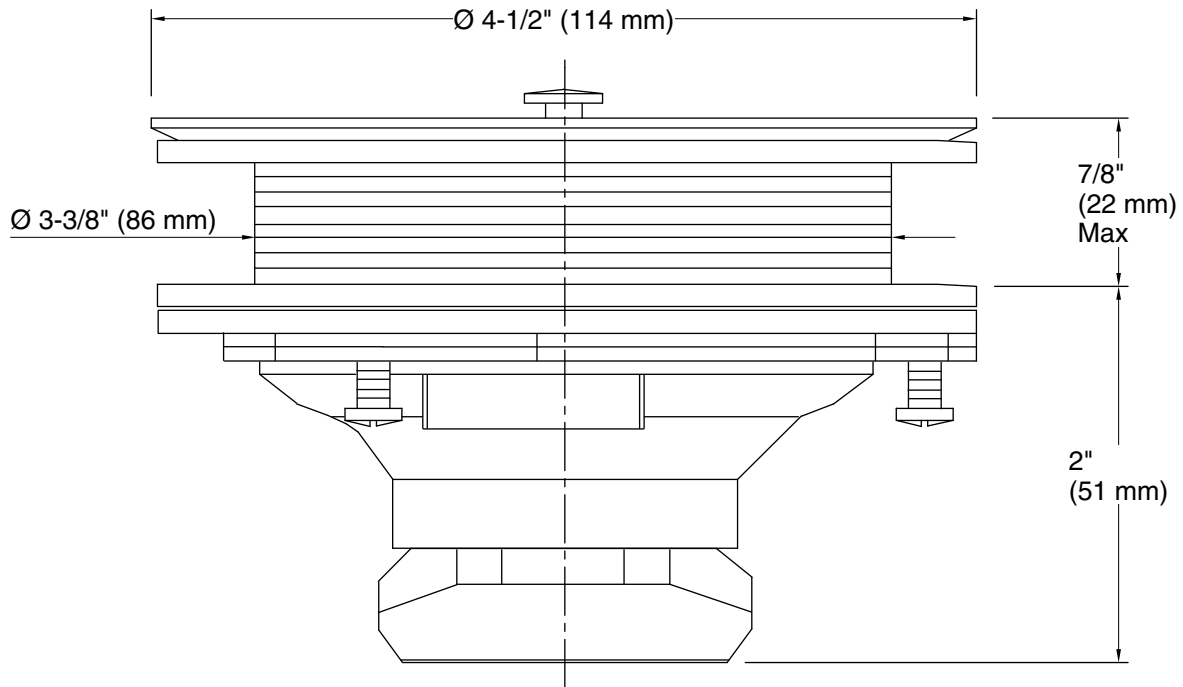
KOHLER® One-Year Limited Warranty

See website for detailed warranty information.

Available Colors/Finishes

Color tiles intended for reference only.

| Color | Code | Description |
|---|------|--------------------------------|
|  | CP | Polished Chrome |
|  | SN | Vibrant™ Polished Nickel |
|  | AF | Vibrant™ French Gold |
|  | PB | Vibrant™ Polished Brass |
|  | BN | Vibrant™ Brushed Nickel |
|  | VS | Vibrant™ Stainless |
|  | BV | Vibrant™ Brushed Bronze |
|  | 2BZ | Oil-Rubbed Bronze |
|  | BL | Matte Black |
|  | 2MB | Vibrant™ Brushed Moderne Brass |



Technical Information

All product dimensions are nominal.