

### Features

- Faceplate with lever handle and push-button diverter
- A single handle controls both on/off activation and temperature setting
- Pressure-balancing diaphragm technology maintains outlet temperature within +/-3°F during water pressure fluctuations
- 5-15/16" (151 mm) nondiverter bath spout with slip-fit connection
- Box includes: Faceplate with lever handle and diverter, shower arm with flange, bath spout
- For use with any KOHLER showerhead (sold separately)
- Coordinates with products in the Hint® collection



### Material

- Premium material construction for durability and reliability
- KOHLER® finishes resist corrosion and tarnishing

### Installation

- Wall-mount
- Trim only; requires K-11748-K or K-11748-KS Rite-Temp pressure-balancing valve (sold separately)

### Required Products/Accessories

K-11748 Series Rite-Temp® Valves

### Recommended Products/Accessories

K-23723 Faucet cleaner

### Optional Products/Accessories

1204798 Deep Rough-in Kit for Rite-Temp Valve

### Codes/Standards





ASME A112.18.1/CSA B125.1


### KOHLER® Faucet Lifetime Limited Warranty

See website for detailed warranty information.

### Available Colors/Finishes

*Color tiles intended for reference only.*

Color	Code	Description
	CP	Polished Chrome
	BN	Vibrant® Brushed Nickel
	BL	Matte Black
	2MB	Vibrant® Brushed Moderne Brass

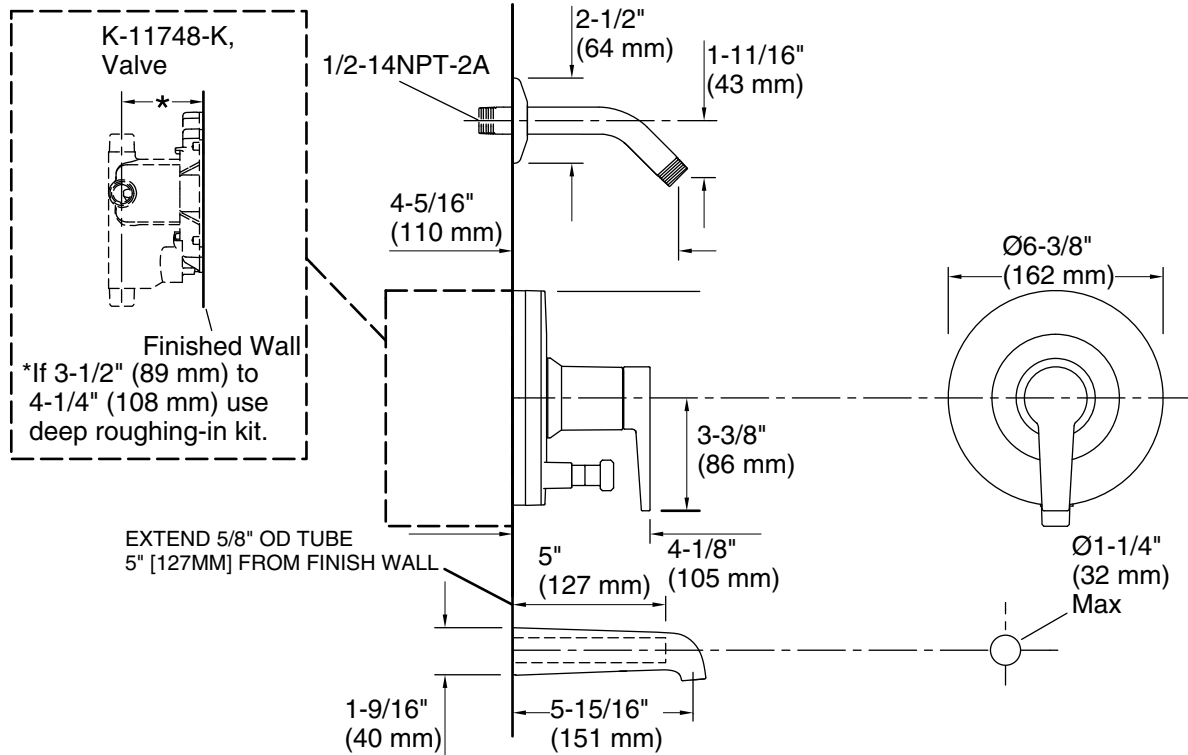

## Technical Information

All product dimensions are nominal.

Drain included: No

### Spout:

Spout reach: 5-15/16" (151 mm)

### Handshower:

Rated maximum flow: 0 gal/min (0 l/min)

## Notes

Avoid cross-flow conditions. Do not install a shut-off device on either valve outlet.