
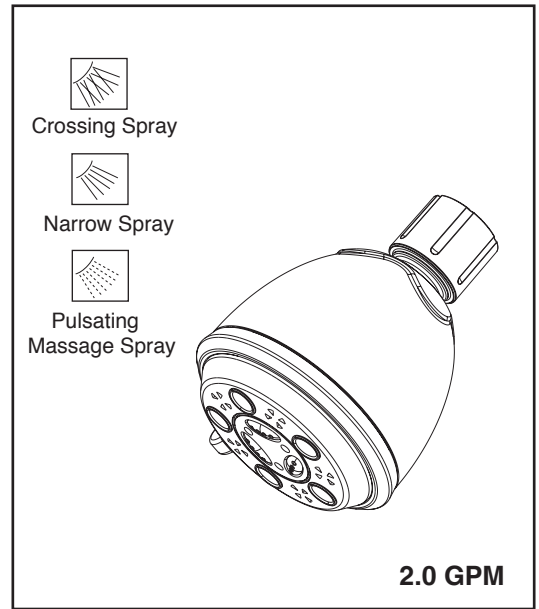
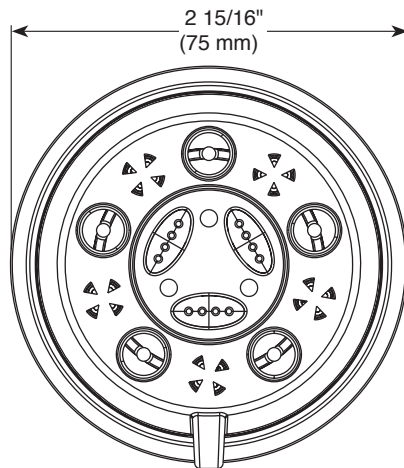


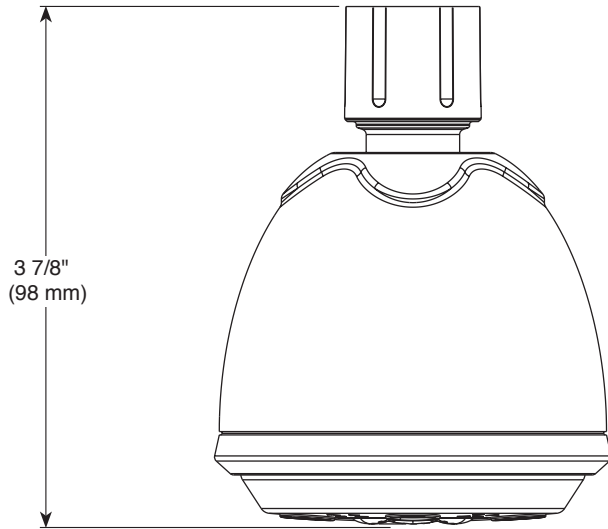

SHOWERHEAD

■ 3-Spray Setting Showerhead

STANDARD SPECIFICATIONS:

- Maximum flow rate 2.0 gpm @ 80 PSI, 7.6L/min @ 552kPa.
- ABS showerhead with three settings - not a positive shut-off.
- Standard 1/2" pipe fitting.
- The ball swivel angle is 17° (8.5° per side).
- Easy-turn spray dial.

WARRANTY

- Lifetime limited warranty on parts (other than electronic parts and batteries) and inishes; or, for commercial users, for 5 years from the date of purchase.
- 5 year limited warranty on electronic parts (other than batteries); or for commercial users, for 1 year from the date of purchase. No warranty is provided on batteries.



COMPLIES WITH

- ASME A112.18.1 / CSA B125.1
- EPA WaterSense®