

Features

- Multifunction handshower offers three spray experiences: wide coverage, intense drenching, and targeted
- Wide coverage spray produces an encompassing spray for everyday use
- Intense drenching spray delivers a forceful spray ideal for rinsing shampoo from hair
- Targeted spray is a focused stream for targeting sore muscles or use as a utility spray
- Handshower holder pivots to adjust the angle of the spray
- Simple thumb tab smoothly transitions between sprays
- Single-function rainhead
- A single handle controls both on/off activation and temperature setting
- MasterClean™ sprayface features an easy-to-clean surface that withstands mineral buildup and maximizes spray performance
- 1.75 gpm (6.6 lpm) maximum flow rate at 45 psi (3.1 bar)
- 60" (1524 mm) hose length
- Adjustable mounting brackets offer installation flexibility
- Includes handshower, rainhead, rainhead arm with flange, wall-mount supply elbow with check valve, 24" slidebar, 60" (1524 mm) hose, valve trim, mounting hardware

Material

- KOHLER® finishes resist corrosion and tarnishing

Installation

- Requires K-8304 or K-28304 series valve (sold separately)
- Requires K-728-K series transfer valve or K-737-K series diverter valve (sold separately)

Included Components

K-10124 Right-angle Shower Arm and Flange
K-22172 Wall-mount supply elbow with check valve
K-72415-G Three-function handshower, 1.75 gpm
K-76464-G 8" single-function rainhead, 1.75 gpm
K-9514 60" Shower Hose
K-98342 Deluxe Slidebar, 24"
K-T97091-4 MasterShower® transfer valve trim
K-TS74042-4 Rite-Temp® valve trim



Codes/Standards

ASME A112.18.1/CSA B125.1
DOE - Energy Policy Act 1992
EPA WaterSense®
California Energy Commission (CEC)
IAPMO Certification


KOHLER® Faucet Lifetime Limited Warranty

See website for detailed warranty information.

Available Colors/Finishes

Color tiles intended for reference only.

Color	Code	Description
	CP	Polished Chrome
	BL	Matte Black
	2MB	Vibrant® Brushed Moderne Brass

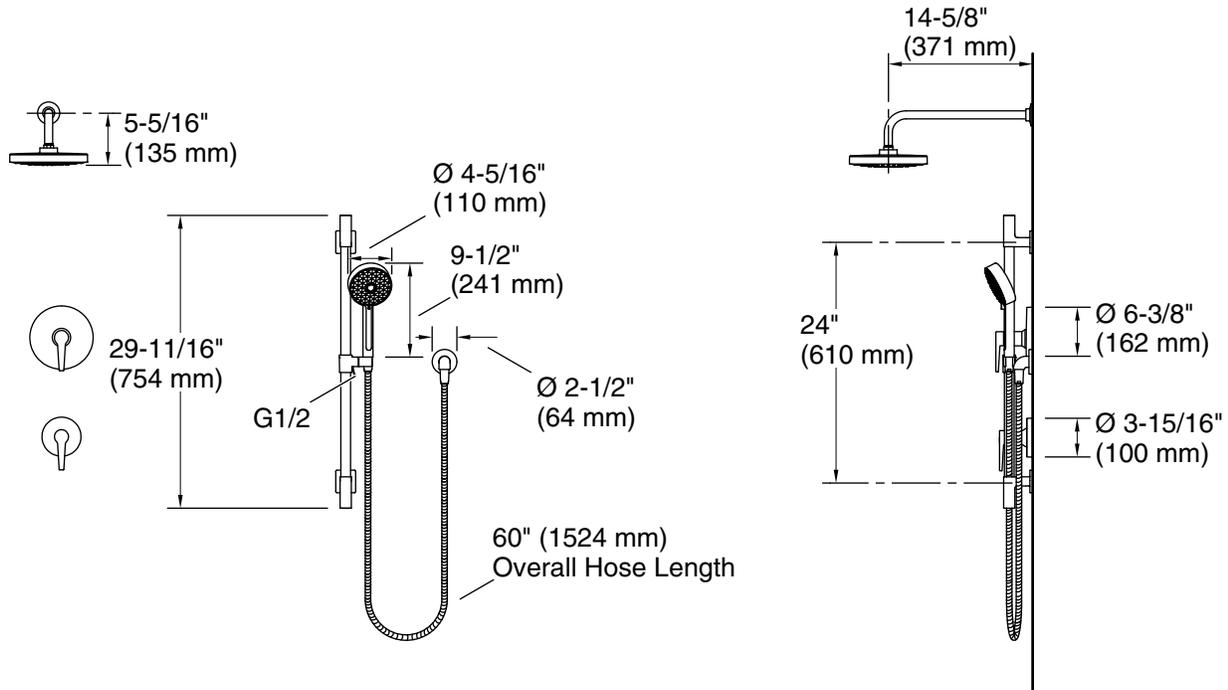

Technical Information

All product dimensions are nominal.

Drain included: No

Handshower:

Rated maximum flow: 1.75 gal/min (6.6 l/min)

Notes

Install this product according to the installation guide.