



A Moen Incorporated Brand

Model: **T41311NHC**



Capstone®



No Head Trims for Pressure Balancing Cycling In-Wall Valve

DESCRIPTION

- Metal construction with various finishes identified by suffix
- Includes arm and flange
- Includes escutcheon and handle
- Includes diverter slip fit tub spout
- Twelve (12) individual boxes per master carton

OPERATION

- Rotating style metal lever handle
- Temperature control by 150° arc
- Will operate with less than 5 lbs of torque
- Stainless steel escutcheon features red and blue molded in color, heat staked temperature indicators that withstand harsh abrasive
- Protective rubber gaskets surround interior and exterior rim
- Weep hole located at bottom of escutcheon
- Slip fit tub spout connects to 1/2" pipe with bottom 5/32" set screw

STANDARDS

- Third party certified to CSA B125.1, ASME A112.18.1, ICC A117.1, IAPMO, and all applicable requirements referenced therein, the Federal Safe Drinking Water Act, California Proposition 65 Illinois, Massachusetts, and Texas
- All CFG products are compliant to all plumbing codes that require 3rd party certification to the applicable plumbing/fitting standards
- Features red/blue hot/cold temperature indicators

- **ADA** for lever handle


WARRANTY — RESIDENTIAL, COMMERCIAL

- Ten year limited warranty against defects in materials and manufacturing workmanship
- Refer to the installation instructions enclosed with each CFG product or call 1-888-450-4910 for complete warranty information


IN-WALL VALVE SOLD SEPARATELY

- 45311 CC/Male IPS with stops
- 45312 CC/Male IPS
- 45317 Female IPS with stops
- 45318 Female IPS
- 45319 PEX connections
- 45320 PEX connections with stops
- 45321 CPVC with stops

CRITICAL DIMENSIONS

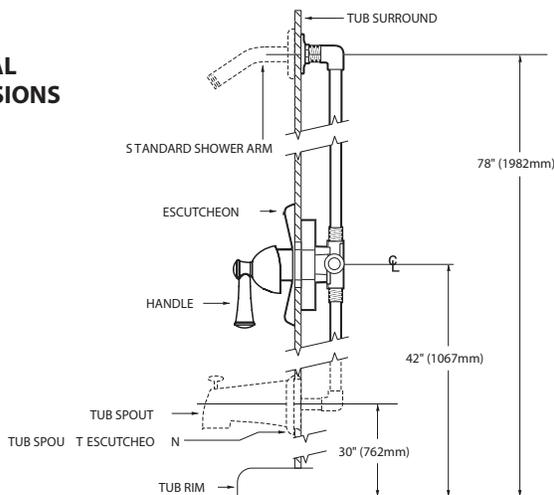

THIN WALL

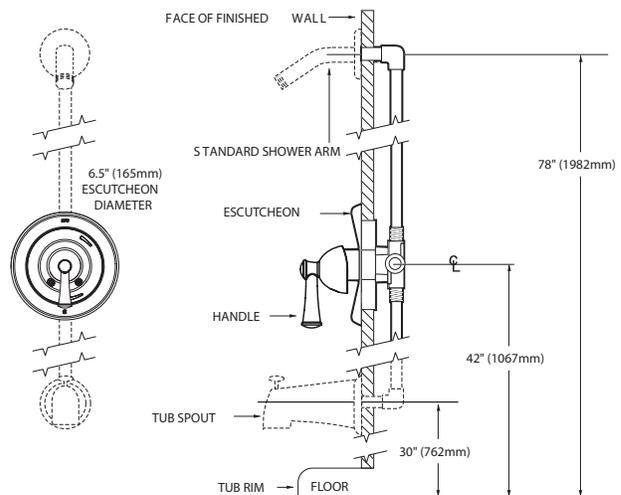

THICK WALL