



Mechanical Dimensions: Inches [mm]

Retail Pack: Inches [mm]

Unless otherwise specified all tolerances are +/- 0.02in (0.5mm)

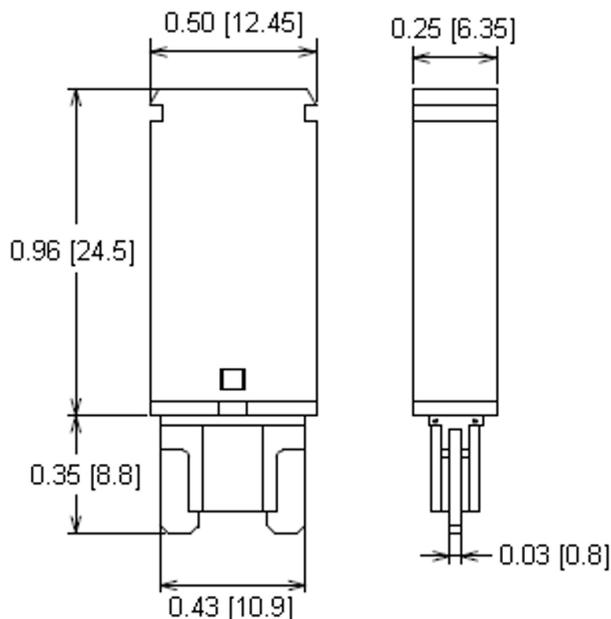

Retail Pack

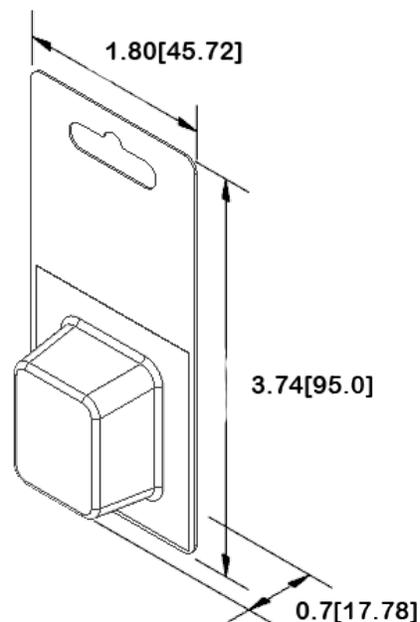

Part Numbers Information

Amperage	Body Color	Bulk Part #	Retail Pack # Blister Card	Pack Size
5A	Tan	ACBP4-PS-5A	ACBP4-PS-5A-BP	1
7.5A	Brown	ACBP4-PS-7.5A	ACBP4-PS-7.5A-BP	1
10A	Red	ACBP4-PS-10A	ACBP4-PS-10A-BP	1
15A	Blue	ACBP4-PS-15A	ACBP4-PS-15A-BP	1
20A	Yellow	ACBP4-PS-20A	ACBP4-PS-20A-BP	1
25A	White	ACBP4-PS-25A	ACBP4-PS-25A-BP	1
30A	Green	ACBP4-PS-30A	ACBP4-PS-30A-BP	1


Electrical Specifications

Voltage Rating	14VDC
Reset Type	Type I - Auto Reset
Operation Temperature	-40°C ~ 85°C
Testing	SAE J553 Type I

Material Specifications

Low Profile, Miniature Blade Circuit Breaker	
Body Material	Thermoplastic – (UL Rated 94V-0)
Terminals Material	Tin plated Copper Alloy

Time vs. Percent of Rated Current

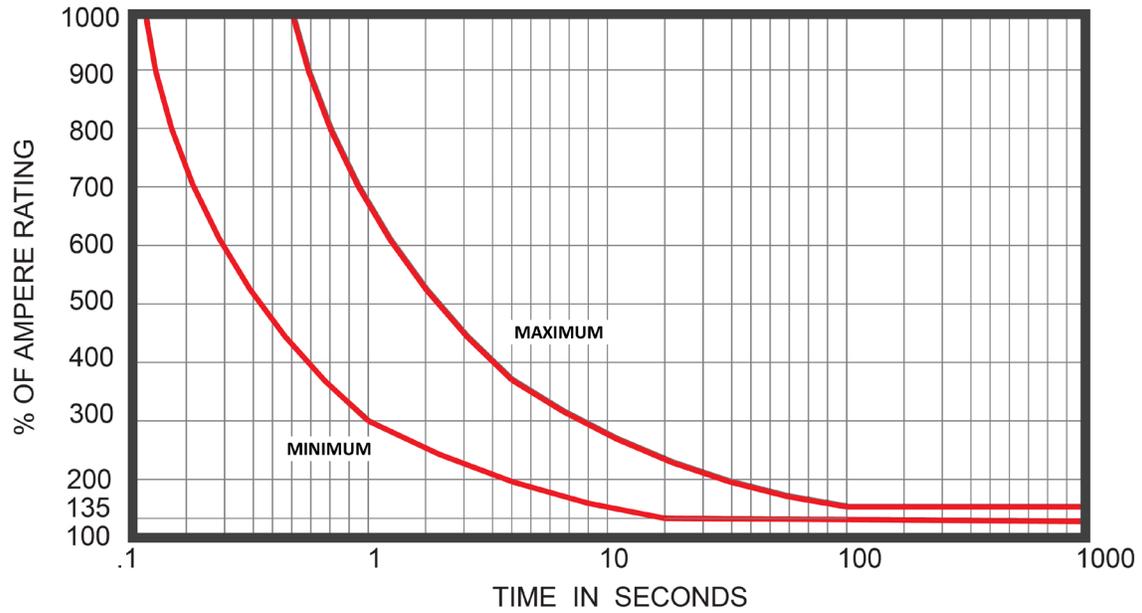

<u>% of Rated Current</u>	<u>Min Hold Time</u>	<u>Max Hold Time</u>
100%	Hold; No Trip	
135%	-	30min
200%	5s	35s
300%	1s	9s

Rev Date of issue Revision Notes

Designed Approved

E	09-30-2024	Updated Time vs. Percent of Rate Current	RC	OF
---	------------	--	----	----