

# Type BLC-10 Fuse Block MGGA Limiter Fuses



www.optifuse.com

(619) 593-5050

## Specifications:

**Base:** NY GF%, Black.

M8 Studs & Nuts & Split Washers: Stainless steel 304

**Cover:** TPV Black.

**Max Fuse Rating:** 500A.

**Max Voltage Rating:** 250VAC; 250VDC

**Recommended Torque**


M8 Stud Torque: 25Nm Minimum

Mounting Torque (Using M6 Bolts & Washers): 10Nm Minimum

**Temperature Rating:** -40°C ~125°C

**Wire Size:** 8mm<sup>2</sup> ~ 30mm<sup>2</sup>

## Mechanical Dimensions: Inches [mm]

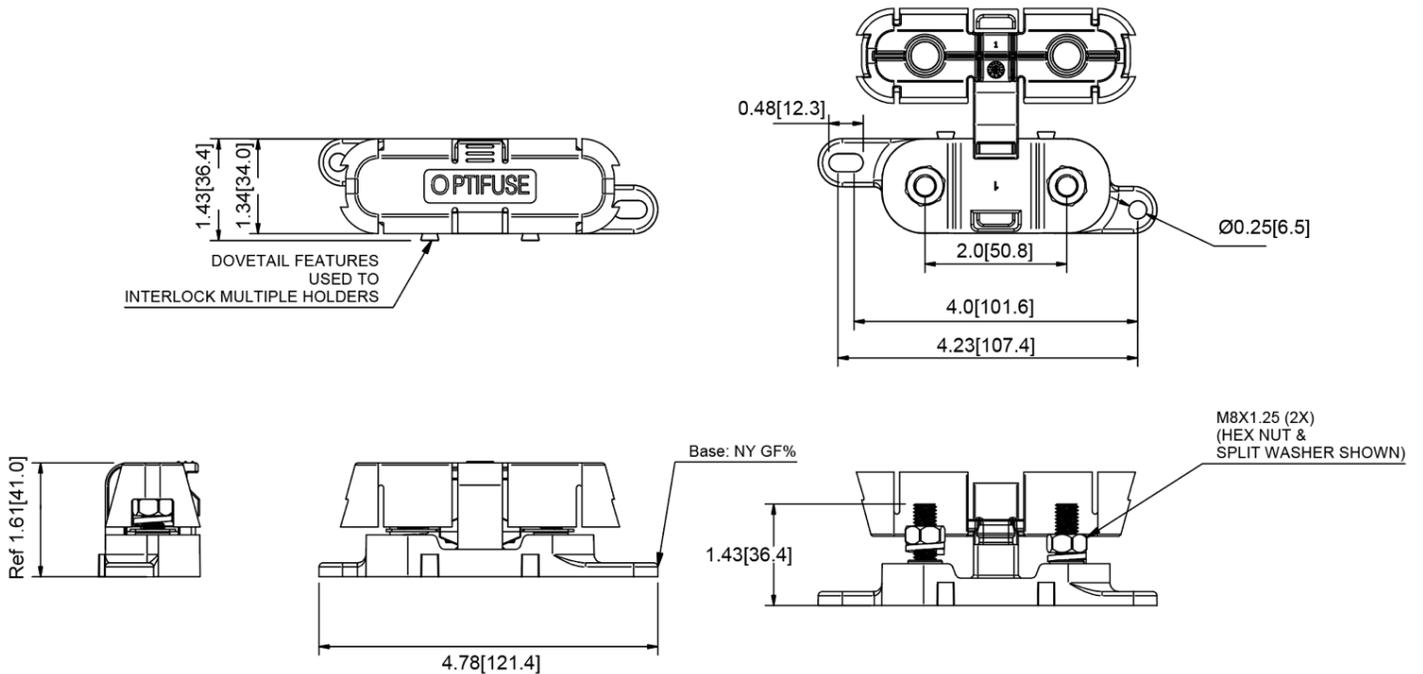

	<p><b>Warning:</b> -Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.</p>
	<p>-Avoid contact of device with chemical solvent. Prolonged contact may damage the device performance.</p>