

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0022552042

Status:


Active

Overview:

SL Modular Connectors

Description:

2.54mm Pitch SL Crimp Housing, Dual Row, Version B, Polarized, 4 Circuits, Black

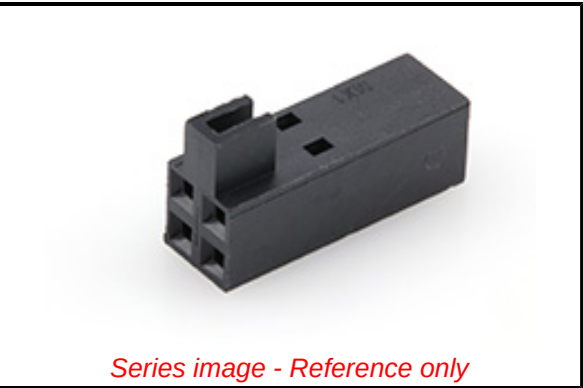

Documents:	
3D Model (PDF)	Product Specification PS-70400-001 (PDF)
3D Model	Packaging Specification PK-70450-100-001 (PDF)
Drawing (PDF)	Test Summary TS-70058-001-001 (PDF)
Product Specification PS-70058-001 (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	70450
Application	Signal, Wire-to-Board
Comments	Version B
Overview	SL Modular Connectors
Product Name	SL
Taxonomy	Connector Housings
UPC	800754395748
Physical	
Breakaway	No
Circuits (maximum)	4
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Polyester
Net Weight	0.370/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	No
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	704500050
Reference - Drawing Numbers	
Packaging Specification	PK-70450-100-001
Product Specification	PS-70058-001, PS-70400-001
Sales Drawing	SD-70450-0050-0075-001
Test Summary	TS-70058-001-001

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -

Halogen-Free

Status

Not Low-Halogen

China RoHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

For more information, please visit [Contact US](#)

Search Parts in this Series

[70450](#) Series

Mates With

C-Grid Right-Angle Header [70229](#) , [70247](#) .

C-Grid Vertical Breakaway Header [70280](#) .

C-Grid Vertical Header [70246](#)

Use With

[70058](#) , [71851](#)