

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0022566107](#)
Status: **Active**
Overview: [SL Modular Connectors](#)
Description: 2.54mm Pitch SL Crimp Housing, Dual Row, Version F, 10 Circuits, Black

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-70450-100-001 \(PDF\)](#)
[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[3D Model \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [70450](#)
 Application Signal, Wire-to-Board
 Comments Version F
 Overview [SL Modular Connectors](#)
 Product Name SL
 Taxonomy Connector Housings
 UPC 800754397926

Physical

Breakaway No
 Circuits (maximum) 10
 Color - Resin Black
 Flammability 94V-0
 Gender Receptacle
 Glow-Wire Capable No
 Material - Resin Polyester
 Net Weight 0.960g
 Number of Rows 2
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 2.54mm
 Stackable No
 Temperature Range - Operating -40° to +105°C

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number 704500253

Reference - Drawing Numbers

Packaging Specification PK-70450-100-001
 Sales Drawing SD-70450-0250-0275-001

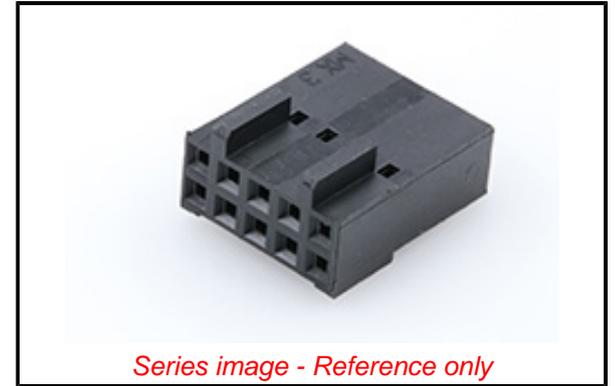

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[70450 Series](#)

Mates With

C-Grid Right-Angle Header [70229](#) , [70247](#) .

C-Grid Vertical Breakaway Header [70280](#) .

C-Grid Vertical Header [70246](#)

Use With

[70058](#) , [71851](#)