

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0029110053](#)
Status: **Active**
Overview: [Mini-Latch Wire-to-Board / Wire-to-Wire Connector System](#)
Description: 2.50mm Pitch Mini-Latch Wire-to-Wire Plug Housing, Friction Lock, without Mounting Ears, 5 Circuits, Natural

Documents:

[3D Model](#) [Product Specification PS-51191-003-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [5240](#)
 Application Signal, Wire-to-Wire
 Overview [Mini-Latch Wire-to-Board / Wire-to-Wire Connector System](#)
 Product Name Mini-Latch
 Taxonomy Connector Housings
 UPC 800753627819

Physical


Circuits (maximum) 5
 Color - Resin Natural (White)
 Flammability 94V-0
 Gender Plug
 Glow-Wire Capable No
 Lock to Mating Part Yes
 Net Weight 791.100/mg
 Number of Rows 1
 Packaging Type Bag
 Panel Mount Yes
 Pitch - Mating Interface 2.50mm
 Stackable No
 Temperature Range - Operating -40° to +105°C

Material Info

Engineering Number 5240-051

Reference - Drawing Numbers

Product Specification PS-51191-003-001
 Sales Drawing SD-5240-N1-001

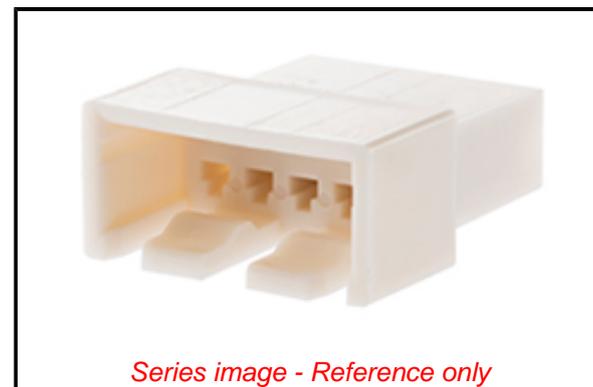

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[5240 Series](#)

Mates With

[51191 Housing](#)

Use With

[5241](#)