


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0151330800
Status: Active
Overview: Pico-Clasp Wire-to-Board Connectors
Description: Pico-Clasp-to-Pico-Clasp Off-the-Shelf (OTS) Cable Assembly, Single Row, 50.00mm Length, 8 Circuits, White

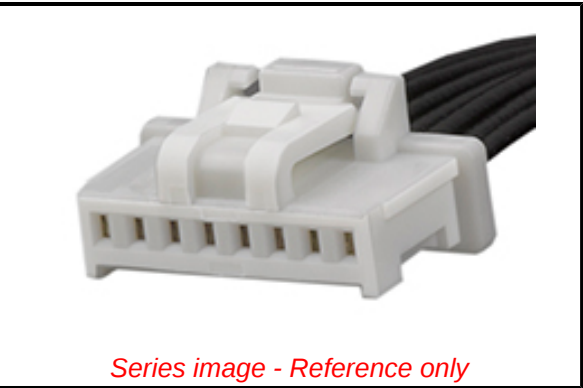

Series image - Reference only

Documents:
[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	15133
Application	Signal, Wire-to-Board
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Pico-Clasp-to-Pico-Clasp
Overmolded	No
Overview	Pico-Clasp Wire-to-Board Connectors
Product Literature Order No	987651-6143
Product Name	Pico-Clasp
Type	Discrete Wire Assembly
UPC	191128140263

Physical	
Cable Length	50.00mm
Circuits (Loaded)	8
Color - Resin	White
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	0.798/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	1.00mm
Plating min - Mating	1.000µm
Plating min - Termination	1.000µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.60mm
Wire Size AWG	28
Wire/Cable Type	UL 1571

Electrical	
Current - Maximum per Contact	1.0A
Voltage - Maximum	50V AC (RMS)/DC

Material Info

Reference - Drawing Numbers	
Sales Drawing	2012341688-000

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per -ED/88/2018 (15 January 2019) Halogen-Free Status Not Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
15133 Series

Mates With
501940 , 203560 , 203561 Vertical PCB Header
501953 , 203562 , 203563 Right Angle PCB Header

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION