

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0366480022](#)
Status: **Active**
Overview: [MLX Power Connectors](#)
Description: 2.13mm Diameter MLX Pin and Socket Receptacle, 2 Circuit, Black

Documents:

Drawing (PDF)	Packaging Specification PK-42022-XX-001 (PDF)
3D Model	Datasheet (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-42022-0001-001 (PDF)	

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	36648
Application	Power, Wire-to-Wire
Comments	Maximum current per contact 20A if used with 36663 and 36664 terminal
Overview	MLX Power Connectors
Product Name	MLX
Taxonomy	Connector Housings
UPC	884982487550

Physical

Circuits (maximum)	2
Color - Resin	Black
Flammability	94V-2
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	2.247/g
Number of Rows	1
Packaging Type	Carton
Panel Mount	Yes
Pitch - Mating Interface	6.35mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-55° to +105°C


Electrical

Current - Maximum per Contact	20.0A
-------------------------------	-------

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-42022-XX-001
Product Specification	PS-42022-0001-001
Sales Drawing	420220000-000, SD-42022-XX-001

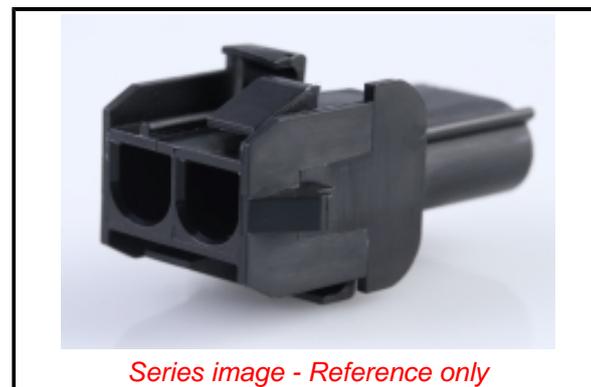

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2022)4187-DC (10 June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[36648](#) Series

Mates With

[42021](#) MLX Power Crimp Housing Plug

Use With

MLX Crimp Terminal [42023](#) , [42024](#)