

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0510350700](#)
Status: **Active**
Overview: [Board-in Connectors](#)
Description: 2.50mm Pitch, Board-In Crimp Housing, Single Row, 7 Circuits, Natural

Documents:

3D Model	Product Specification PS-51035-002-001 (PDF)
3D Model (PDF)	Packaging Specification SPK-51035-001-001 (PDF)
Drawing (PDF)	Packaging Specification SPK-51035-001-002 (PDF)
Product Specification PS-51035-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Crimp Housings
Series	51035
Application	Signal
Overview	Board-in Connectors
Product Name	Board-in
Taxonomy	Connector Housings
UPC	800754298599


Physical

Circuits (maximum)	7
Color - Resin	Natural
Gender	N/A
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	310.400/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm
Stackable	No
Temperature Range - Operating	-40° to +105°C

Material Info

Reference - Drawing Numbers

Packaging Specification	SPK-51035-001-001, SPK-51035-001-002
Product Specification	PS-51035-001-001, PS-51035-002-001
Sales Drawing	SD-51035-001-001

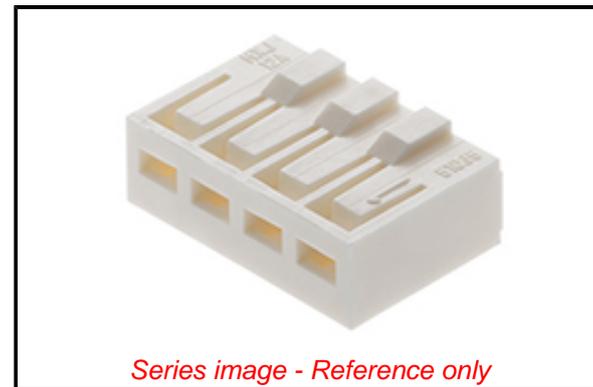

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[51035 Series](#)

Use With

[50097](#)