

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0511911100

Status:


Active

Overview:

Mini-Latch Wire-to-Board / Wire-to-Wire Connector System

Description:

2.50mm Pitch Mini-Latch Wire-to-Wire and Wire-to-Board Receptacle Housing, with Guide Rails, 11 Circuits

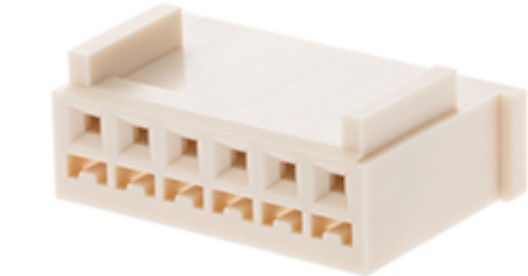

Series image - Reference only

Documents:	
3D Model	Product Specification PS-51191-003-001 (PDF)
Drawing (PDF)	Application Specification 511910000-AS-000 (PDF)
3D Model (PDF)	Packaging Specification 511919200-SPK-200 (PDF)
Product Specification 2055050000-PS-000 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification 511910000-PS-000 (PDF)	

Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	51191
Application	Signal, Wire-to-Board, Wire-to-Wire
Overview	Mini-Latch Wire-to-Board / Wire-to-Wire Connector System
Product Name	Mini-Latch
Taxonomy	Connector Housings
UPC	800753327887
Physical	
Circuits (maximum)	11
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	1047.200/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm
Stackable	No
Temperature Range - Operating	-40° to +105°C
Material Info	
Reference - Drawing Numbers	
Application Specification	511910000-AS-000
Packaging Specification	511919200-SPK-200
Product Specification	2055050000-PS-000, 511910000-PS-000, PS-51191-003-001
Sales Drawing	SD-51191-004-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

51191 Series

Mates With

5045 Vertical Header . 5046 Right Angle Header . 5240 Plug Housing

Use With

50802 Crimp Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION