

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0533751510](#)  
**Status:** **Active**  
**Overview:** Mini-Lock Wire-to-Board Connector System  
**Description:** 2.50mm Pitch, Mini-Lock PCB Header, Single Row, Vertical, Through Hole with Kinked Pins, Tin Plating, Positive Lock, 15 Circuits, Bag, 3.40mm PC Tail Length

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Packaging Specification 533759200-SPK-200 (PDF)</a>
<a href="#">3D Model</a>	<a href="#">Packaging Specification SPK-53375-001-001 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Packaging Specification SPK-53375-001-002 (PDF)</a>
<a href="#">Product Specification 511630000-PS-000 (PDF)</a>	<a href="#">Datasheet (PDF)</a>
<a href="#">Product Specification 511631000-PS-000 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-51103-005-001 (PDF)</a>	

**Agency Certification**


CSA	LR19980
UL	E29179

**General**

Product Family	PCB Headers
Series	<a href="#">53375</a>
Application	Signal, Wire-to-Board
Overview	<a href="#">Mini-Lock Wire-to-Board Connector System</a>
Product Name	Mini-Lock
Taxonomy	PCB Headers and Receptacles
UPC	800753437999

**Physical**

Breakaway	No
Circuits (Loaded)	15
Circuits (maximum)	15
Color - Resin	Natural
Durability (mating cycles max)	30
First Mate / Last Break	No
Flammability	94V-0
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	1550.000/mg
Number of Rows	1
Orientation	Vertical
PC Tail Length	3.40mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Bag
Pitch - Mating Interface	2.50mm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Shrouded	Fully
Stackable	No
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Through Hole - Kinked Pin

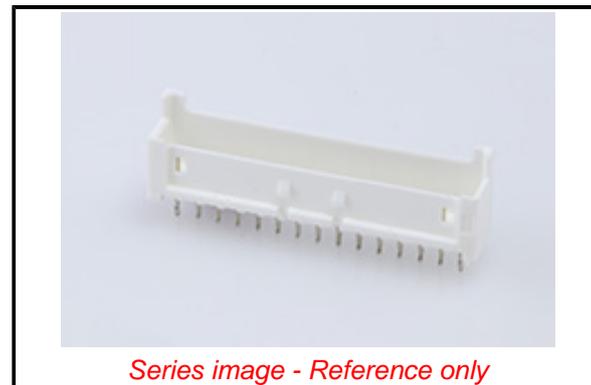

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2022)4187-DC (10  
June 2022)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[53375 Series](#)

**Mates With**

Mini-Lock Receptacle [51163](#) . Mini-Lock  
Cable Assembly [15137](#)

**Electrical**

Current - Maximum per Contact

3.0A

Voltage - Maximum

250V AC (RMS)/DC

**Material Info****Reference - Drawing Numbers**

Packaging Specification

533759200-SPK-200, SPK-53375-001-001,  
SPK-53375-001-002

Product Specification

511630000-PS-000, 511631000-PS-000,  
PS-51103-005-001

Sales Drawing

533750000-SD-000

This document was generated on 10/17/2022

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**