

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0901430106

Status:


Active

Overview:

C-Grid III Interconnects

Description:

2.54mm Pitch C-Grid III Modular Crimp Housing, Dual Row, 4 Polarizing Buttons, 6 Circuits, Black

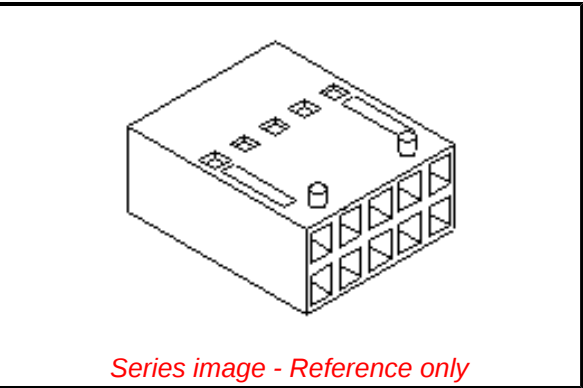

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification PS-99020-0001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	90143
Application	Signal, Wire-to-Board
Comments	4 Polarizing Buttons
Overview	C-Grid III Interconnects
Product Name	C-Grid III
Taxonomy	Connector Housings
UPC	800753538887
Physical	
Breakaway	No
Circuits (maximum)	6
Circuits Detail	No Voided Circuits
Color - Resin	Black
Flammability	94V-1
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	No
Material - Resin	PPO
Net Weight	0.342/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Pitch - Termination Interface	2.54mm
Polarized to Mating Part	No
Ports	1
Stackable	Yes
Temperature Range - Operating	-55° to +105°C

Material Info

Reference - Drawing Numbers

Product Specification

Sales Drawing

PS-99020-0001-001

SD-90143-001

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per - D(2022)4187-DC (10 June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

90143 Series

Mates With

C-Grid III Right-Angle Header [90122](#) . C-Grid III Header [90130](#) . C-Grid III Vertical Header [90131](#)

Use With

C-Grid III Crimp Terminal [90119](#)
 C-Grid III Pre-Crimped Lead [797582022](#) , [797582023](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION