

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0901560165

Status:


Active

Overview:

C-Grid III Interconnects

Description:

2.54mm Pitch C-Grid III Crimp Housing Single Row, 25 Circuits, Black

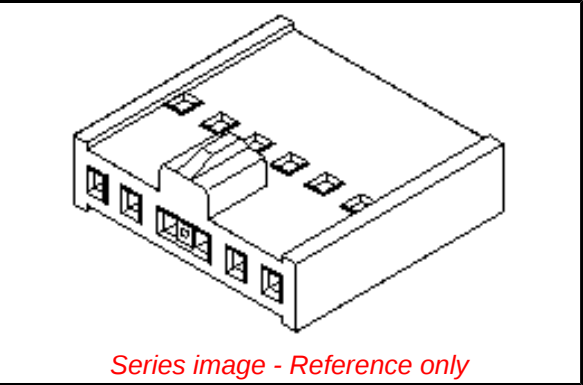

Documents:	
3D Model	Application Specification 901190001-AS-000 (PDF)
Drawing (PDF)	Packaging Specification PK-90156-0001-001 (PDF)
Product Specification PS-99020-0001-001 (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	90156
Application	Signal, Wire-to-Board
Overview	C-Grid III Interconnects
Product Name	C-Grid III
Taxonomy	Connector Housings
UPC	800753529670
Physical	
Breakaway	No
Circuits (maximum)	25
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	PPO
Net Weight	1.875/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Temperature Range - Operating	-55° to +105°C
Material Info	
Reference - Drawing Numbers	
Application Specification	901190001-AS-000
Packaging Specification	PK-90156-0001-001
Product Specification	PS-99020-0001-001
Sales Drawing	SDA-90156-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

Green Image

REACH SVHC

Not Contained Per - D(2022)4187-DC (10 June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

Green Image

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series
90156 Series

Mates With
C-Grid III Vertical Header [90120](#) , [90136](#) . C-Grid III Right-Angle Header [90121](#)

Use With
C-Grid III Crimp Terminal [90119](#) . C-Grid III Pre-Crimped Lead [797582022](#) , [797582023](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION